

Features

- Easy fasten in application with a screw or bolt.
- Spring steel bright zinc plated
- Reusable so could be repositioned.
- Widely used across many industries or commercial and domestic situations
- Widely recyclable

RS PRO Spring Clips

RS Stock No.: see below



RS PRO Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.


Product Description

Narrow Base Tool Clips are manufactured from High Carbon Spring Steel strip and Bright Zinc Plated for corrosion resistance.

These clips are widely used in many Industries and are also available with a white or black coated finish.

All clips usually have one fixing hole, however sizes over 50.8mm have two fixings. (RS 175-3586 and RS 175-3587).

General Specifications

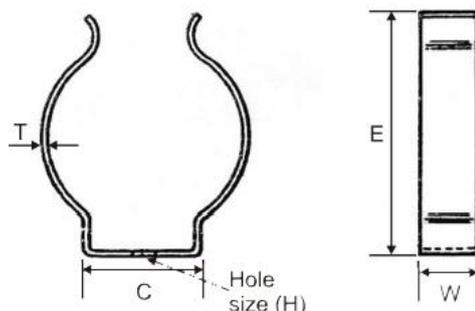

RS part No	Size		H *		W		T		C		E	
	Inch	mm	Inch	mm	Inch	mm	Inch	mm	Inch	mm	Inch	mm
1753576	1/4	6.35	.092	2.34	1/4	6.35	.0148	.376	11/64	4.37	13/32	10.32
1753577	3/8	9.53	.093	2.34	1/4	6.35	.0148	.376	13/64	5.16	33/64	13.10
1753578	1/2	12.70	.115	2.92	5/16	7.94	.0180	.457	15/64	5.95	41/64	16.27
1753579	5/8	15.88	.147	3.73	5/16	7.94	.0180	.457	19/64	7.54	25/32	19.84
1753580	3/4	19.05	.163	4.14	3/8	9.53	.0200	.508	25/64	9.92	1.1/32	26.19
1753582	1	25.40	.163	4.14	3/8	9.53	.0280	.711	1/2	12.70	1.21/64	33.73
1753583	1.1/8	28.58	.163	4.14	3/8	9.53	.0320	.813	17/32	13.49	1.31/64	37.70
1753584	1.1/4	31.75	.163	4.14	3/8	9.53	.0320	.813	37/64	14.68	1.21/32	42.07
1753585	1.1/2	38.10	.163	4.14	3/8	9.53	.0360	.914	21/32	16.67	1.7/8	47.63
1753588	1.3/4	44.45	.198	5.03	1/2	12.7	.0400	1.02	51/64	20.24	2.13/64	55.96
1753586	2	50.80	.613	4.14	1/2	12.7	.0400	1.02	55/64	21.83	2.13/32	61.12
1753587	2.1/2	63.50	.187	4.75	3/4	19.05	.0400	1.02	1.3/8	35.00	2.7/8	73.00

*H: Hole diameter - above dimensions are in the off-press condition, coating can reduce hole diameters.