



0010418


Jingweitang Industrial Zone,
Dalingshan Town, Dongguan City

Sales: Ms. Wang

Mobile number : +86 189-4861-7861

Web: [Http://www.yufengciye.com](http://www.yufengciye.com)

E-mail: yufengciye@126.com

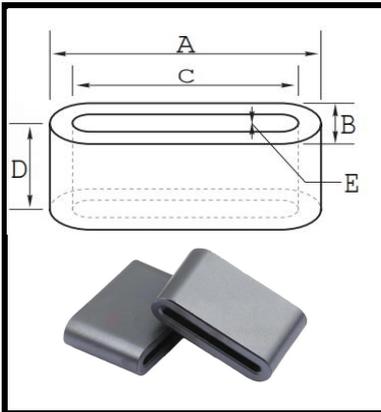

Product Category	Core Marking			Coating Color
	Lot Number	Part Number	Inductance Grade	
Ferrite Core	2601	0010418	N/A	No

Dimensions	Uncoated		Coated Limits			Packaging Box Qty=448PCS
	(mm)	(in)		(mm)	(in)	
OD (A)	23.50	0.926	B	3.01	0.12	
ID (C)	20.02	0.789	E	1.05	0.04	
HT (D)	5.05	0.199	-	-	-	

Electrical Characteristics			Physical Characteristics						
IMPEDANCE RESULT (Testing Condition:0.65x0.5TSx120mm)			Initial Permeability	Saturation Magnetic Flux Density	Remanence	Coercivity	Density	Material	Weight (g)
@100Mhz	80Ω	50%							

The Limit of Breakage					Temperature Rating		
Winding Length Per Turn		Wound Coil Dimensions (mm)			Curie Temp: >250°C		
Winding Factor	(mm)	Winding Factor	(mm)	40% Winding Factor	OD	-	
				HT	-		
-	-	-	-	Completely Full Window	Max OD	-	
-	-	-	-		Max HT	-	
				Surface Area (mm ²)		Notes:	
				Unwound Core			-
				40% Winding Factor			-
					Coating Temp (Continuous up to): 180°C		

IMPEDANCE V.S FREQUENCY

