



0040525


Jingweitang Industrial Zone,
Dalingshan Town, Dongguan City

Sales: Ms. Wang

Mobile number : +86 189-4861-7861

Web: [Http://www.yufengciye.com](http://www.yufengciye.com)

E-mail: yufengciye@126.com

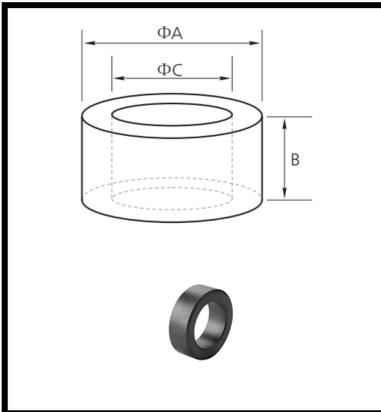

Product Category	Core Marking			Coating Color
	Lot Number	Part Number	Inductance Grade	
Ferrite Core	2601	0040525	N/A	Green

Dimensions	Uncoated		Coated Limits			Packaging Box Qty=300 pcs
	(mm)	(in)	(mm)	(in)		
OD (A)	25.33	0.998	26.09	1.028	MAX	
ID (C)	15.25	0.601	14.49	0.571	MIN	
HT (B)	12.05	0.475	12.77	0.503	MAX	

Electrical Characteristics			Physical Characteristics							
IMPEDANCE RESULT (Testing Condition:0.55x0.5TSx120mm)			Permeability	Saturation Magnetic Flux Density	Remanence	Coercivity	Density	Material	AL(nH/T ²)	
			@25Mhz	45Ω	26°C	850	410 (4kA/m)	200	45.0	5.1
@100Mhz	80Ω	50%								

WATT LOSS					Temperature Rating		
Winding Length Per Turn				Wound Coil Dimensions (mm)			Curie Temp: >250°C
Winding Factor	(mm)	Winding Factor	(mm)	40% Winding Factor	OD	-	Coating Temp (Continuous up to): 180°C
					HT	-	
				Completely Full Window	Max OD	-	Notes:
					Max HT	-	
				Surface Area (mm ²)			
				Unwound Core	-		
				40% Winding Factor	-		

IMPEDANCE V.S FREQUENCY

