



YUFENGCIYE

0010623


Jingweitang Industrial Zone,
Dalingshan Town, Dongguan City

Sales: Ms. Wang

Mobile number : +86 189-4861-7861

Web: [Http://www.yufengciye.com](http://www.yufengciye.com)

E-mail: yufengciye@126.com

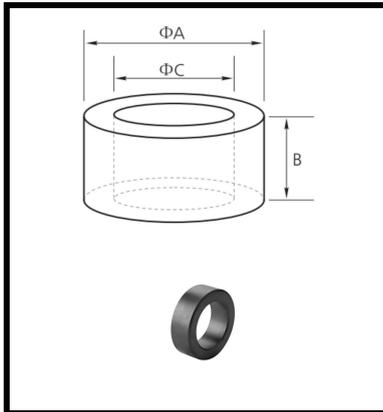

Product Category	Core Marking			Coating Color
	Lot Number	Part Number	Inductance Grade	
Ferrite Core	2601	0010623	N/A	Green

Dimensions	Uncoated		Coated Limits			Packaging
	(mm)	(in)	(mm)	(in)		
OD (A)	35.75	1.409	36.25	1.428	MAX	Box Qty=40 pcs
ID (C)	23.10	0.910	22.75	0.896	MIN	
HT (B)	12.78	0.504	13.52	0.533	MAX	

Electrical Characteristics			Physical Characteristics						
IMPEDANCE RESULT (Testing Condition:0.65x0.5TSx120mm)			Initial Permeability	Saturation Magnetic Flux Density	Remanence	Coercivity	Density	Material	Weight (g)
			900	320 (4kA/m)	140	20.0	5.1	NZO	37.3
@25Mhz	55Ω	26°C							
@100Mhz	100Ω	50%							

The Limit of Breakage					Temperature Rating	
Winding Length Per Turn		Wound Coil Dimensions (mm)			Curie Temp: -30°C-110°C	
Winding Factor	(mm)	Winding Factor	(mm)	40% Winding Factor	OD	-
					HT	-
				Completely Full Window	Max OD	-
					Max HT	-
				Surface Area (mm ²)		Notes:
				Unwound Core	-	
				40% Winding Factor	-	

IMPEDANCE V.S FREQUENCY

