



0010418


Jingweitang Industrial Zone,
Dalingshan Town, Dongguan City

Sales: Ms. Wang

Mobile number : +86 189-4861-7861

Web: [Http://www.yufengciye.com](http://www.yufengciye.com)

E-mail: yufengciye@126.com

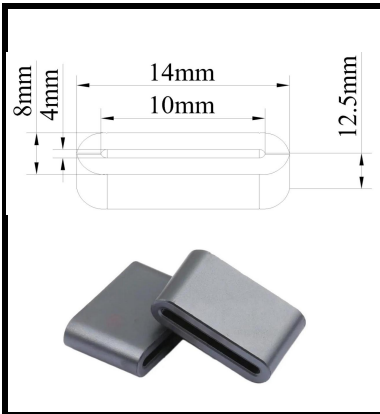

Product Category	Core Marking			Coating Color
	Lot Number	Part Number	Inductance Grade	
Ferrite Core	2601	0010418	N/A	No

Dimensions	Uncoated		Coated Limits		Packaging
	(mm)	(in)	(mm)	(in)	
OD (A)	14.05	0.554	-	-	MAX
ID (C)	10.02	0.395	-	-	MIN
HT (B)	12.55	0.494	-	-	MAX


Box Qty=3600

Electrical Characteristics			Physical Characteristics						
IMPEDANCE RESULT (Testing Condition:0.65x0.5TSx120mm)			Initial Permeability	Saturation Magnetic Flux Density	Remanence	Coercivity	Density	Material	Weight (g)
@100Mhz	80Ω	50%							

The Limit of Breakage					Temperature Rating	
Winding Length Per Turn		Wound Coil Dimensions (mm)			Curie Temp: -30°C-110°C	
Winding Factor	(mm)	Winding Factor	(mm)	40% Winding Factor	OD	-
					HT	-
				Completely Full Window	Max OD	-
					Max HT	-
				Surface Area (mm ²)		
				Unwound Core		-
				40% Winding Factor		-

Notes:

IMPEDANCE V.S FREQUENCY

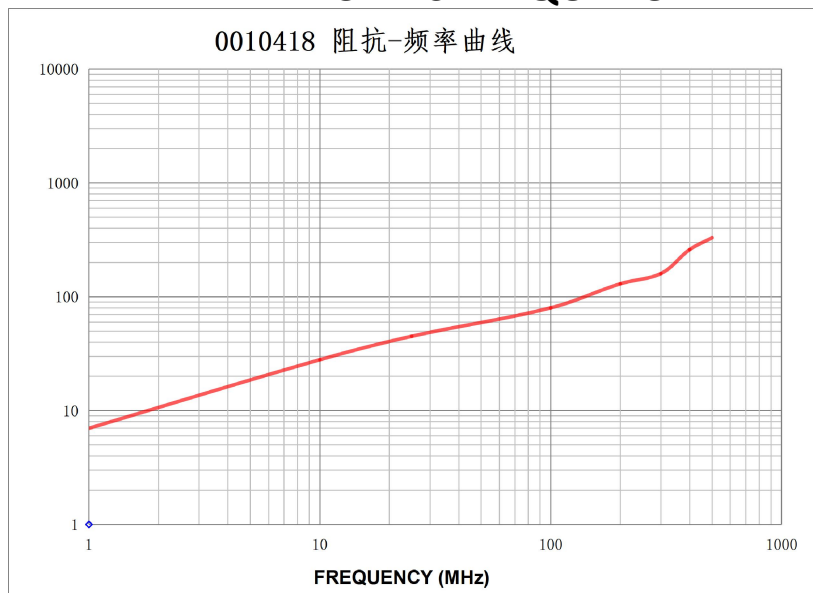

Revision 10/8/2025

