



YUFENGCIYE

**0020373**


Jingweitang Industrial Zone,  
Dalingshan Town, Dongguan City

Sales: Ms. Wang

Mobile number : +86 189-4861-7861

Web: [Http://www.yufengciye.com](http://www.yufengciye.com)

E-mail: [yufengciye@126.com](mailto:yufengciye@126.com)

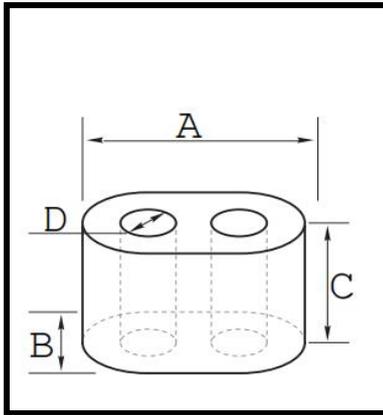

Product Category	Core Marking			Coating Color
	Lot Number	Part Number	Inductance Grade	
Ferrite Core	2601	0020373	N/A	No

Dimensions	Uncoated		Uncoated		Packaging
	(mm)	(in)	(mm)	(in)	
OD (A)	12.95	0.510	(B)	7.50	Box Qty=3600
ID (D)	3.70	0.146	-	-	
HT (C)	14.35	0.565	-	-	

Electrical Characteristics			Physical Characteristics						
<b>IMPEDANCE RESULT</b> (Testing Condition:0.65x0.5TSx120mm)			Initial Permeability	Saturation Magnetic Flux Density	Remanence	Coercivity	Density	Material	Weight (g)
@100Mhz	210Ω	50%							

The Limit of Breakage					Temperature Rating	
Winding Length Per Turn			Wound Coil Dimensions (mm)		Curie Temp: -30°C-110°C	
Winding Factor	(mm)	Winding Factor	(mm)	40% Winding Factor	OD	-
				HT	-	
-	-	-	-	Completely Full Window	Max OD	-
-	-	-	-		Max HT	-
Surface Area (mm <sup>2</sup> )					Notes:	
Unwound Core					-	
40% Winding Factor					-	

**IMPEDANCE V.S FREQUENCY**

