



YUFENGCIYE

**0010475**


Jingweitang Industrial Zone,  
Dalingshan Town, Dongguan City

Sales: Ms. Wang

Mobile number : +86 189-4861-7861

Web: [Http://www.yufengciye.com](http://www.yufengciye.com)

E-mail: [yufengciye@126.com](mailto:yufengciye@126.com)

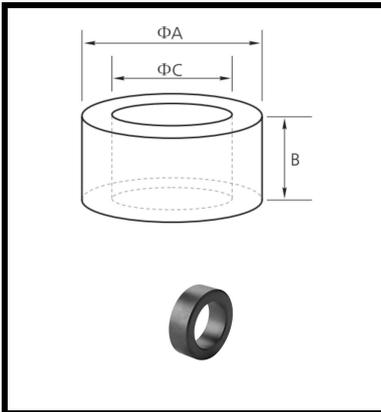

Product Category	Core Marking			Coating Color
	Lot Number	Part Number	Inductance Grade	
Ferrite Core	2601	0010475	N/A	No

Dimensions	Uncoated		Coated Limits		Packaging
	(mm)	(in)	(mm)	(in)	
OD (A)	48.02	1.892	49.25	1.940	MAX
ID (C)	26.05	1.026	25.52	1.005	MIN
HT (B)	16.05	0.632	16.89	0.665	MAX
					Box Qty=18 pcs

Electrical Characteristics			Physical Characteristics						
<b>IMPEDANCE RESULT</b> (Testing Condition:0.65x0.5TSx120mm)			Initial Permeability	Saturation Magnetic Flux Density	Remanence	Coercivity	Density	Material	Weight (g)
@100Mhz	125Ω	50%							

The Limit of Breakage					Temperature Rating	
Winding Length Per Turn			Wound Coil Dimensions (mm)		Curie Temp: -30°C-110°C	
Winding Factor	(mm)	Winding Factor	(mm)	40% Winding Factor	OD	-
				HT	-	
-	-	-	-	Completely Full Window	Max OD	-
-	-	-	-		Max HT	-
Surface Area (mm <sup>2</sup> )					Notes:	
-	-	-	-	Unwound Core	-	
-	-	-	-	40% Winding Factor	-	

**IMPEDANCE V.S FREQUENCY**

