



0010884


Jingweitang Industrial Zone,
Dalingshan Town, Dongguan City

Sales: Ms. Wang

Mobile number : +86 189-4861-7861

Web: [Http://www.yufengciye.com](http://www.yufengciye.com)

E-mail: yufengciye@126.com

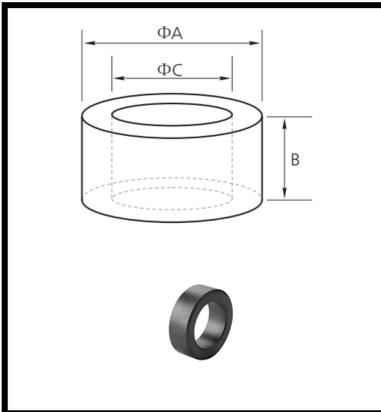

Product Category	Core Marking			Coating Color
	Lot Number	Part Number	Inductance Grade	
Ferrite Core	2601	0010884	N/A	Green

Dimensions	Uncoated		Coated Limits			Packaging Box Qty=300 pcs
	(mm)	(in)	(mm)	(in)		
OD (A)	28.45	1.121	29.30	1.155	MAX	
ID (C)	13.82	0.545	13.13	0.517	MIN	
HT (B)	28.65	1.129	30.37	1.197	MAX	

Electrical Characteristics			Physical Characteristics						
IMPEDANCE RESULT (Testing Condition:0.65x0.5TSx120mm)			Initial Permeability	Saturation Magnetic Flux Density	Remanence	Coercivity	Density	Material	Weight (g)
@100Mhz	295Ω	50%							

The Limit of Breackage					Temperature Rating		
Winding Length Per Turn		Wound Coil Dimensions (mm)			Curie Temp: >160°C		
Winding Factor	(mm)	Winding Factor	(mm)	40% Winding Factor	OD	-	Coating Temp (Continuous up to): 180°C
					HT	-	
				Completely Full Window	Max OD	-	Notes:
					Max HT	-	
				Surface Area (mm ²)			
				Unwound Core	-		
				40% Winding Factor	-		

IMPEDANCE V.S FREQUENCY

