



YUFENGCIYE

0010284


Jingweitang Industrial Zone,
Dalingshan Town, Dongguan City

Sales: Ms. Wang

Mobile number : +86 189-4861-7861

Web: [Http://www.yufengciye.com](http://www.yufengciye.com)

E-mail: yufengciye@126.com

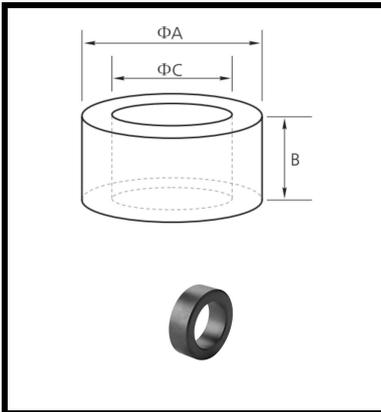

Product Category	Core Marking			Coating Color
	Lot Number	Part Number	Inductance Grade	
Ferrite Core	2601	0010284	N/A	No

Dimensions	Uncoated		Coated Limits		Packaging
	(mm)	(in)	(mm)	(in)	
OD (A)	23.07	0.909	23.76	0.936	Box Qty=150 pcs
ID (C)	13.52	0.533	12.84	0.506	
HT (B)	19.05	0.751	19.81	0.781	

Electrical Characteristics			Physical Characteristics						
IMPEDANCE RESULT (Testing Condition:0.5x2TSx120mm)			Initial Permeability	Saturation Magnetic Flux Density	Remanence	Coercivity	Density	Material	Weight (g)
@100Mhz	420Ω	50%	1200	360 (1.6kA/m)	140	20.0	5.1	NZO	20.5

The Limit of Breakage					Temperature Rating	
Winding Length Per Turn		Wound Coil Dimensions (mm)			Curie Temp: >160°C	
Winding Factor	(mm)	Winding Factor	(mm)	40% Winding Factor	OD	-
					HT	-
				Completely Full Window	Max OD	-
					Max HT	-
				Surface Area (mm ²)		
				Unwound Core	-	
				40% Winding Factor	-	
Notes:						

IMPEDANCE V.S FREQUENCY

