



0010329


Jingweitang Industrial Zone,
Dalingshan Town, Dongguan City

Sales: Ms. Wang

Mobile number : +86 189-4861-7861

Web: [Http://www.yufengciye.com](http://www.yufengciye.com)

E-mail: yufengciye@126.com

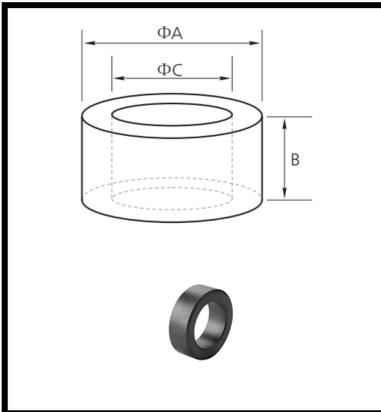

Product Category	Core Marking			Coating Color
	Lot Number	Part Number	Inductance Grade	
Ferrite Core	2601	0010329	N/A	Green

Dimensions	Uncoated		Coated Limits		Packaging
	(mm)	(in)	(mm)	(in)	
OD (A)	30.88	1.217	31.81	1.253	Box Qty=54 pcs
ID (C)	19.05	0.751	18.10	0.713	
HT (B)	21.95	0.865	23.27	0.917	

Electrical Characteristics			Physical Characteristics						
IMPEDANCE RESULT (Testing Condition:0.5x0.5TSx120mm)			Initial Permeability	Saturation Magnetic Flux Density	Remanence	Coercivity	Density	Material	Weight (g)
			1200	360 (<1.6kA/m)	140	20.0	5.1	NZO	48.0
@25Mhz	85Ω	26°C							
@100Mhz	130Ω	50%							

The Limit of Breakage					Temperature Rating	
Winding Length Per Turn			Wound Coil Dimensions (mm)			Curie Temp: >160°C
Winding Factor	(mm)	Winding Factor	(mm)	40% Winding Factor	OD	Coating Temp (Continuous up to): 180°C
					HT	
-	-	-	-	Completely Full Window	Max OD	Notes:
-	-	-	-		Max HT	
				Surface Area (mm ²)		
				Unwound Core		-
				40% Winding Factor		-

IMPEDANCE V.S FREQUENCY

