



0010251


Jingweitang Industrial Zone,
Dalingshan Town, Dongguan City

Sales: Ms. Wang

Mobile number : +86 189-4861-7861

Web: [Http://www.yufengciye.com](http://www.yufengciye.com)

E-mail: yufengciye@126.com

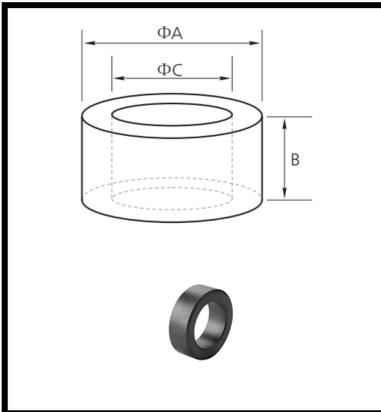

Product Category	Core Marking			Coating Color
	Lot Number	Part Number	Inductance Grade	
Ferrite Core	2601	0010251	N/A	No

Dimensions	Uncoated		Coated Limits			Packaging
	(mm)	(in)	(mm)	(in)		
OD (A)	25.05	0.987	20.65	0.814	MAX	Box Qty= 603 pcs
ID (C)	15.08	0.594	9.21	0.363	MIN	
HT (B)	10.20	0.402	5.25	0.207	MAX	

Electrical Characteristics			Physical Characteristics						
IMPEDANCE RESULT (Testing Condition:0.65x0.5TSx120mm)			Initial Permeability	Saturation Magnetic Flux Density	Remanence	Coercivity	Density	Material	Weight (g)
@100Mhz	80Ω	50%							

The Limit of Breackage					Temperature Rating	
Winding Length Per Turn		Wound Coil Dimensions (mm)			Curie Temp: -30°C-110°C	
Winding Factor	(mm)	Winding Factor	(mm)	40% Winding Factor	OD	-
					HT	-
				Completely Full Window	Max OD	-
					Max HT	-
				Surface Area (mm ²)		
				Unwound Core	-	
				40% Winding Factor	-	
Notes:						

IMPEDANCE V.S FREQUENCY

