



YUFENGCIYE

0020373


Jingweitang Industrial Zone,
Dalingshan Town, Dongguan City

Sales: Ms. Wang

Mobile number : +86 189-4861-7861

Web: [Http://www.yufengciye.com](http://www.yufengciye.com)

E-mail: yufengciye@126.com

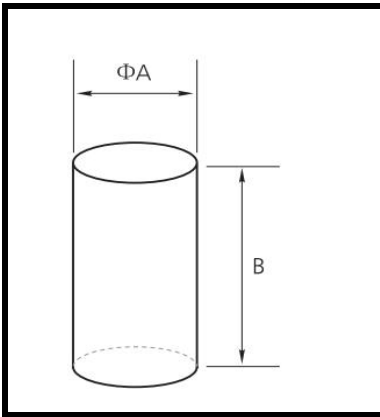

Product Category	Core Marking			Coating Color
	Lot Number	Part Number	Inductance Grade	
Ferrite Core	2601	0020373	N/A	No

Dimensions	Uncoated		Uncoated		Packaging
	(mm)	(in)	(mm)	(in)	
OD (A)	10.21	0.402	-	-	Box Qty=343 PCS
ID (D)	-	-	-	-	
HT (B)	30.05	1.184	-	-	

Electrical Characteristics		Physical Characteristics						
TEST RESULT (Testing Condition:0.65x10TS)		Initial Permeability	Saturation Magnetic Flux Density	Remanence	Coercivity	Density	Material	Weight (g)
AL:>4.0uH	@1Khz,1V,	850	410 (4kA/m)	140	20.0	5.1	NZO	11.5

The Limit of Breakage				Temperature Rating	
Winding Length Per Turn		Wound Coil Dimensions (mm)		Curie Temp: -30°C-110°C	
Winding Factor	(mm)	Winding Factor	(mm)	40% Winding Factor	OD -
					HT -
-	-	-	-	Completely Full Window	Max OD -
-	-	-	-		Max HT -
-	-	-	-	Surface Area (mm ²)	
-	-	-	-	Unwound Core	-
-	-	-	-	40% Winding Factor	-

