



YUFENGCIYE

**0050836**


Jingweitang Industrial Zone,  
Dalingshan Town, Dongguan City

Sales: Ms. Wang

Mobile number : +86 189-4861-7861

Web: [Http://www.yufengciye.com](http://www.yufengciye.com)

E-mail: [yufengciye@126.com](mailto:yufengciye@126.com)

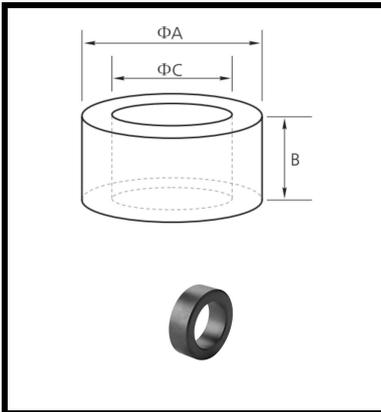

Product Category	Core Marking			Coating Color
	Lot Number	Part Number	Inductance Grade	
Ferrite Core	2601	0050836	N/A	Green

Dimensions	Uncoated		Coated Limits			Packaging Box Qty=280 pcs
	(mm)	(in)	(mm)	(in)		
OD (A)	27.56	1.086	28.39	1.118	MAX	
ID (C)	15.62	0.615	14.84	0.585	MIN	
HT (B)	13.22	0.521	14.01	0.552	MAX	

Electrical Characteristics			Physical Characteristics						
<b>IMPEDANCE RESULT</b> (Testing Condition:0.55x1TSx120mm)			Initial Permeability	Saturation Magnetic Flux Density	Remanence	Coercivity	Density	Material	AL(nH/T <sup>2</sup> )
@100Mhz	130Ω	50%							

WATT LOSS					Temperature Rating	
Winding Length Per Turn		Wound Coil Dimensions (mm)			Curie Temp: >160°C	
Winding Factor	(mm)	Winding Factor	(mm)	40% Winding Factor	OD	Coating Temp (Continuous up to): 180°C
					HT	
-	-	-	-	Completely Full Window	Max OD	Notes:
-	-	-	-		Max HT	
Surface Area (mm <sup>2</sup> )						
Unwound Core						
40% Winding Factor						

**IMPEDANCE V.S FREQUENCY**

