



# 0010115


Jingweitang Industrial Zone,  
Dalingshan Town, Dongguan City

Sales: Ms. Wang

Mobile number : +86 189-4861-7861

Web: [Http://www.yufengciye.com](http://www.yufengciye.com)

E-mail: [yufengciye@126.com](mailto:yufengciye@126.com)

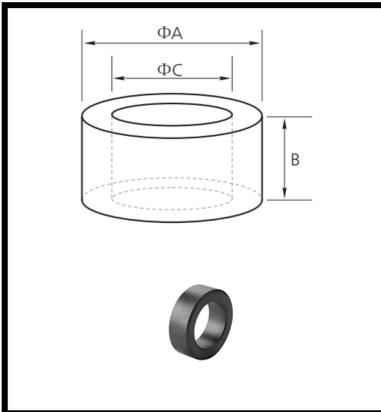


Product Category	Core Marking			Coating Color
	Lot Number	Part Number	Inductance Grade	
Ferrite Core	2601	0010115	N/A	Black

Dimensions	Uncoated		Coated Limits			Packaging Box Qty= 2300 pcs
	(mm)	(in)	(mm)	(in)		
OD (A)	11.68	0.460	11.68	0.460	MAX	
ID (C)	5.05	0.199	4.80	0.189	MIN	
HT (B)	24.85	0.979	25.85	1.018	MAX	

Electrical Characteristics			Physical Characteristics						
<b>IMPEDANCE RESULT</b> (Testing Condition:0.65x0.5TSx120mm)			Initial Permeability	Saturation Magnetic Flux Density	Remanence	Coercivity	Density	Material	Weight (g)
@100Mhz	265Ω	50%							

The Limit of Breakage					Temperature Rating		
Winding Length Per Turn		Wound Coil Dimensions (mm)			Curie Temp: -30°C-110°C		
Winding Factor	(mm)	Winding Factor	(mm)	40% Winding Factor	OD	-	Coating Temp (Continuous up to): 180°C
				HT	-		
-	-	-	-	Completely Full Window	Max OD	-	Notes:
-	-	-	-		Max HT	-	
-	-	-	-	Surface Area (mm <sup>2</sup> )			
-	-	-	-	Unwound Core	-		
-	-	-	-	40% Winding Factor	-		

## IMPEDANCE V.S FREQUENCY

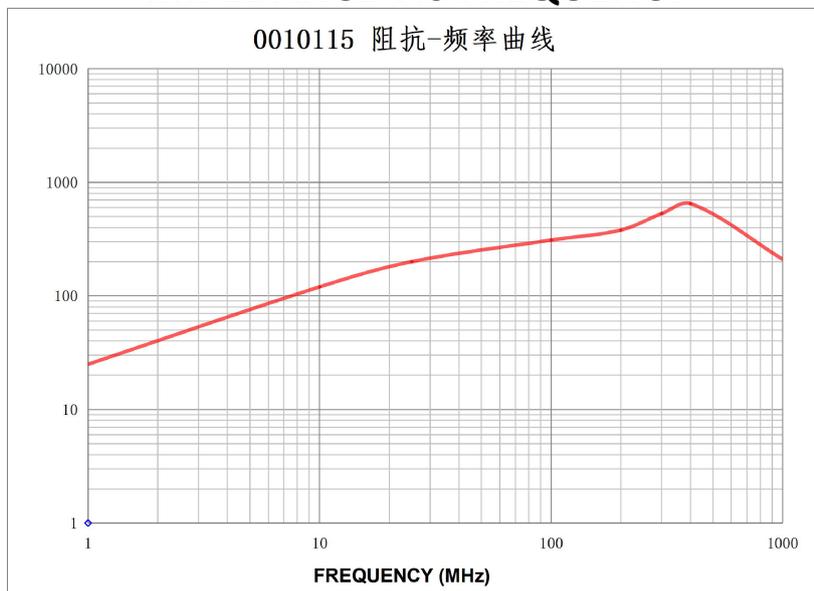

Revision 10/8/2025

