



YUFENGCIYE

0010882


Jingweitang Industrial Zone,
Dalingshan Town, Dongguan City

Sales: Ms. Wang

Mobile number : +86 189-4861-7861

Web: [Http://www.yufengciye.com](http://www.yufengciye.com)

E-mail: yufengciye@126.com

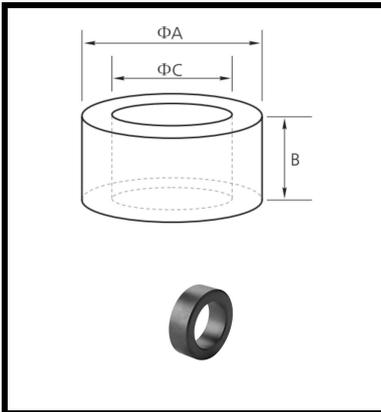

| Product Category | Core Marking | | | Coating Color |
|------------------|--------------|-------------|------------------|---------------|
| | Lot Number | Part Number | Inductance Grade | |
| Ferrite Core | 2601 | 0010882 | N/A | Green |

| Dimensions | Uncoated | | Coated Limits | | | Packaging |
|------------|----------|-------|---------------|-------|-----|-----------------|
| | (mm) | (in) | (mm) | (in) | | |
| OD (A) | 18.15 | 0.715 | 18.69 | 0.737 | MAX | Box Qty=120 pcs |
| ID (C) | 11.05 | 0.435 | 10.50 | 0.414 | MIN | |
| HT (B) | 28.52 | 1.124 | 30.23 | 1.191 | MAX | |

| Electrical Characteristics | | | Physical Characteristics | | | | | | |
|---|------|------|--------------------------|----------------------------------|-----------|------------|---------|----------|------------|
| IMPEDANCE RESULT (Testing Condition:0.65x0.5TSx120mm) | | | Initial Permeability | Saturation Magnetic Flux Density | Remanence | Coercivity | Density | Material | Weight (g) |
| | | | 1500 | 320 (1.6kA/m) | 140 | 7.0 | 5.1 | NZO | 22.5 |
| @25Mhz | 120Ω | 26°C | | | | | | | |
| @100Mhz | 150Ω | 50% | | | | | | | |

| The Limit of Breakage | | | | Temperature Rating | |
|-------------------------|------|----------------------------|------|---------------------------------|----------|
| Winding Length Per Turn | | Wound Coil Dimensions (mm) | | Curie Temp: >160°C | |
| Winding Factor | (mm) | Winding Factor | (mm) | 40% Winding Factor | OD - |
| | | | | | HT - |
| | | | | Completely Full Window | Max OD - |
| | | | | | Max HT - |
| | | | | Surface Area (mm ²) | |
| | | | | Unwound Core | - |
| | | | | 40% Winding Factor | - |
| Notes: | | | | | |

IMPEDANCE V.S FREQUENCY

