


技术参数:

1. 做用温度: $-25 \sim +85^{\circ}\text{C}$;
2. 额定负荷: DC 12V 50mA;
3. 接触电阻: $\leq 50\text{m}\Omega$;
4. 绝缘电阻: $\geq 100\text{M}\Omega$;
5. 耐压: AC250V (50Hz)/min;
6. 动作力: $260 \pm 50\text{g}$;
7. 使用寿命: 100000次;

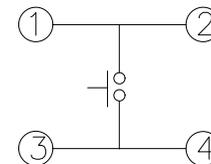

电路图

Part NO.	H 高度
HC-6602-2.5-260G-L	2.5
HC-6602-3.1-260G-L	3.1
HC-6602-3.5-260G-L	3.5
HC-6602-3.8-260G-L	3.8

序号	名称	数量	材料	镀层/颜色	备件
5	接触脚	1	黄铜	镀银	
4	基座	1	PPA (黑色)	---	
3	盖板	1	不锈钢	铜锡	
2	簧片	1	不锈钢	---	
1	硅胶帽头	1	硅胶	蓝色	

序号 No.	变更内容 MODIFY CONTENT	日期 MODIFY DATE	GENERAL TOLERANCE	制图 DRAWING	审核 CHECK
1	初版发行		DIM TOL		
			X.X ± 0.30	批准 APPROVAL	
			X.XX ± 0.20	比例 SCALE	
			X.XXX ± 0.10	投影 Projection	
			Angle $\pm 3.0^{\circ}$		

深圳市华灿天禄电子有限公司
ShenzhenhuacantianluELECTRONICS CO., LTD

产品名称 TITLE	轻触开关 (SMT 6.5x6.4mm 蓝头)	版本 REV.	A
产品料号 PART NO.	HC-6602-3.5-260G-L	单位 UNITS	mm
材料 MATERIAL		页次 SHEET	1/1