



Military-Fasteners.com

P/N NAS662C2R3

Description

length: 3/16", thread: 2-56, 70,000 psi tensile strength, flat head, corrosion resistant steel, cruciform recess, philips, NAS662 series screw

* Manufacturer certifications are shipped with your order FREE of charge


Order this part online

Additional Information

Alternate Part Numbers

[NAS662-C2R3](#)

SKU / Model:	NAS662C2R3
Minimum Qty (MOQ):	100
NSN:	5305-00-866-2295
Schedule B:	7318.15.6080
ECCN:	EAR99
National Motor Freight:	093486, Bolts,nuts Or Screws, Noi (sub 3)

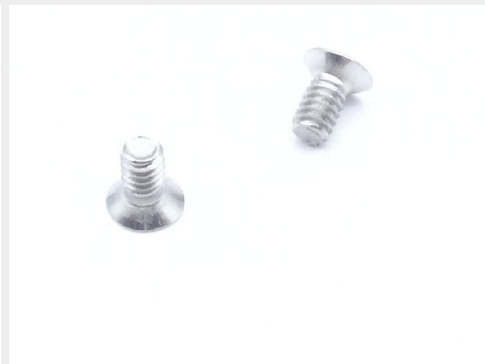

* See page 2 for technical characteristics

P/N NAS662C2R3 Specifications

Thread Class:	2a
Thread Direction:	Right-hand
Thread Length:	0.152 Inches Minimum And 0.188 Inches Maximum
Fastener Length:	0.156 Inches Minimum And 0.188 Inches Maximum
Head Style:	Flat Countersunk
Head Diameter:	0.156 Inches Minimum And 0.172 Inches Maximum
Internal Drive Style:	Cross Recess Type 1
Nominal Thread Diameter:	0.086 Inches
Thread Quantity Per Inch:	56
Minimum Tensile Strength:	80000 Pounds Per Square Inch
Countersink Angle:	99.0 Degrees Minimum And 101.0 Degrees Maximum
Screw Material:	Steel Comp 302 Or Steel Comp 303 Or Steel Comp 321 Or Steel Comp 347
Screw Surface Treatment:	Passivate
Screw Surface Treatment Document And Classification:	Qq-p-35 Fed Spec Single Treatment Response
Thread Series Designator:	Unc

How to Order

Order this machine screw from our inventory online by visiting <https://military-fasteners.com/screws/machine+screws/NAS662C2R3> and selecting the quantity you want then click "add to cart". Once items are in your cart you can check out [here](#) to complete your order.