


P.C.B LAYOUT
BOTTOM VIEW


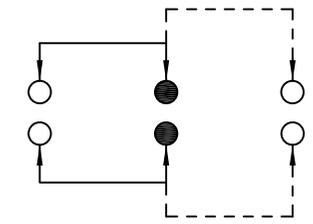


SCHEMATIC (SHORTING)

SK-22D14-GXXX

横柄
G-Switch P/N

- Switch Height (mm)
- G020=2.0 G030=3.0
 - G040=4.0 G050=5.0
 - G055=5.5 G060=6.0
 - G065=6.5 G070=7.0
 - G075=7.5 G080=8.0
 - G085=8.5 G090=9.0
 - G095=9.5 G100=10.0

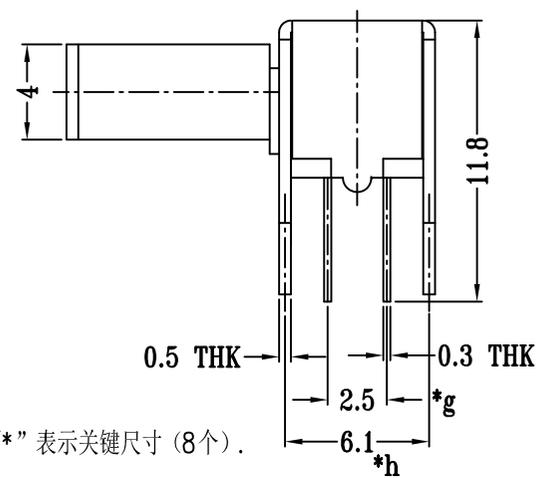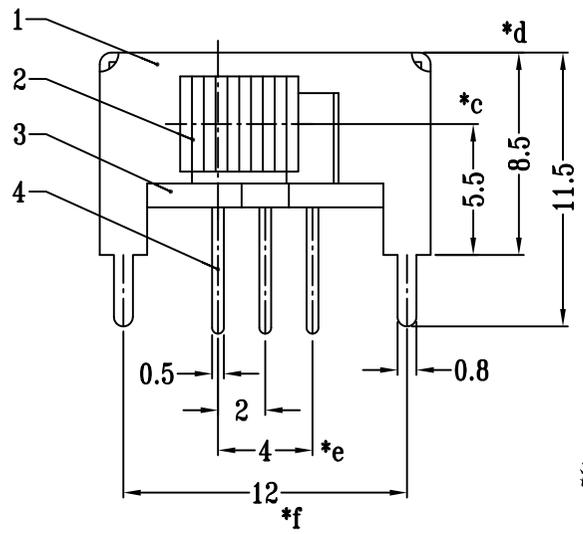

注：“*”表示关键尺寸（8个）.

G-Switch Specification:

Electrical Specifications: 1.0A/DC24V
 Contact resistance (CR): ≤50mΩ
 Insulation Resistance(IR): ≥100MΩ DC250V
 Compressive strength (WV): AC250V 1minute
 Operating temperature: -25°C~+70°C
 Storage humidity: <85%RH
 Electrical life: 10,000Cycles.



		G-Switch Electronic (HongKong) CO.,Ltd.				
				DESIGN Bright Lee	DATE 2016.05.29	Molde code:
Unless otherwise specified, Tolerance: X. ±0.30 X.x ±0.20 X.xx ±0.15 X.xxx ±0.10 Angles ±3°		CHECKED	DATE	SK-22D14-GXXX		
		APPROVED	DATE			
		http://www.dg-switch.com		REV.: X1	SCALE: 4:1	UNIT: mm
		TEL:0769-82388879		SIZE: A4	SHEET: 1/1	