


External Dimensions (Unit:mm)

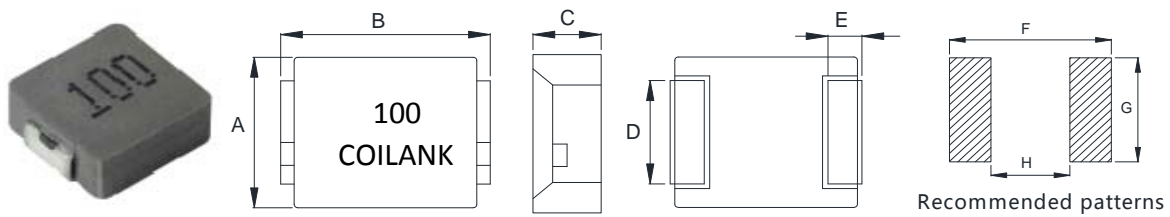

TYPE	A	B Max	C Max	D typ	E typ	F typ	G typ	H typ	Q'TY/Reel
APS13D65	12.6±0.3	13.8	6.5	4.7	2.4	14.7	5.0	8.3	500

Part Number Code

APS	1365	M	100	DW
Series Name	Dimensions: L*W*H	Tolerance 20%	Inductan	Internal controls

APS Series

Part Number	Inductance (μ H) @100KHz/1V	DC Resistance (m Ω) Max.	Heat Rating Current I _{rms} (A)Typ.	Saturation Current I _{sat} (A)Typ.
APS1365M1R0DW	1	2.1	32	41.07
APS1365M1R5DW	1.5	3	26	38.76
APS1365M2R2DW	2.2	4.5	21	32.87
APS1365M3R3DW	3.3	6	18.3	28.75
APS1365M4R7DW	4.7	8.7	15	25.25
APS1365M6R8DW	6.8	11.3	13.8	20.43
APS1365M100DW	10	17.2	11	18.43
APS1365M150DW	15	28.2	8.7	11.13
APS1365M220DW	22	40	7	10.47
APS1365M330DW	33	69	5.5	7.66
APS1365M470DW	47	104	4.2	7.15