


YX-A11-R301730-G3240



APPLICATIONS

- Cross outlet
- Coil attached square
- diskette, size: 30mm
- Double-sided magnetic tape
- Attach the coil to double-sided tape
Double line tinning

SHAPE & DIMENSIONS

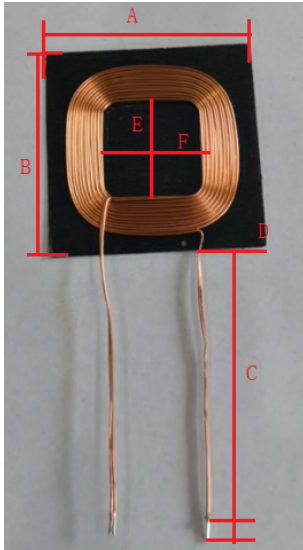

Symbol	A	B	C	D	E	F
Value(mm)	30.0±1.00	30.0±1.00	40.00±3	3.00±1.00	14.00±1.00	14.00±1.00

AIR COIL SPECIFICATIONS

Number of Coils	Wire Diameters	Turns Ratio
1	∅:0.3mm*2P	17TS

MAXIMUM RATINGS

Operating Temperature / Humidity	Storage Temperature / Humidity
-40 to +85°C / 10 to 65% R.H. R.H.	-25 to +125°C / 10 to 65%

ELECTRICAL CHARACTERISTICS

OCL [100kHz 0.1V] (μH)	DCR [100kHz 0.1V] (mΩ)	WPC Compliant
13 ± 10%	35max.	Yes

PACKAGING : Bagging

Dimensions (mm)		Quantity (pcs)	
Tray	—	Qty per tray	—
Small carton	320x320x55	Qty per small carton	50
Outer carton	350x350x180	Qty per outer carton	2000

OTHERS

Weight (g) typ.	5..90
--------------------	-------