

19" Rack Cabinet




RA Series

RA series, the 19" industrial standard cabinets that heights range from 15U to 42U. It has been widely used with MEAN WELL's 3+N product line; there are also brackets, fixed shelves, vented rack panels, blanking panels and cooling fans and other accessories meet customer installation needs. The products are suitable for system power supplies, servers, audio visual control, monitoring systems and storage devices.

Features


- The surface coated with electrostatic powder, which is dust-proof, anti-oxidation, not easy to scratch, and resistant to acid and alkali
- There are no screw parts on the side panels of the cabinet, so as the upper and lower frames; keeps the overall appearance clean
- In order to increase the wiring space, the front width of the cabinet is increased to 600mm while the internal remains a standardized frame of 19 inches
- Three 4-inch module fans can be installed on the top of the cabinet; optional modules of 110V/220V for purchase & self-assemble (Standard cabinets are configured with blanking panels)
- Equipped with braked wheels and leveling screws to maintain the balance of the cabinet and prevent it from shaking

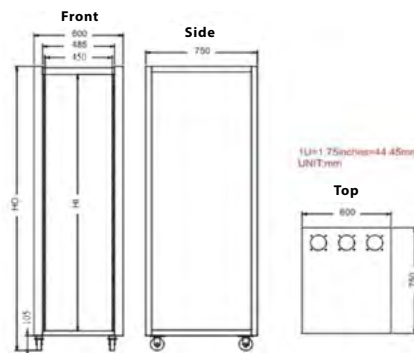

Part No.	Photo	Dimensions (HxWxD)	Internal Height	Internal Width	Internal depth
RA-15U-750		912x600x750mm	667mm	450mm	660mm
RA-22U-750		1224x600x750mm	979mm	450mm	660mm
RA-30U-750		1579x600x750mm	1334mm	450mm	660mm
RA-35U-750		1801x600x750mm	1556mm	450mm	660mm
RA-42U-750		2112x600x750mm	1867mm	450mm	660mm

Part No.	Photo	Dimensions (HxWxD)	Place of Production	Load	Safety
RA-15U-750-C		External: 912x600x750mm Internal: 667x450x660mm	China		
RA-22U-750-C		External: 1224x600x750mm Internal: 979x450x660mm			
RA-30U-750-C		External: 1579x600x750mm Internal: 1334x450x660mm			
RA-35U-750-C		External: 1801x600x750mm Internal: 1556x450x660mm			
RA-42U-750-C		External: 2112x600x750mm Internal: 1867x450x660mm			

Assembly Diagram

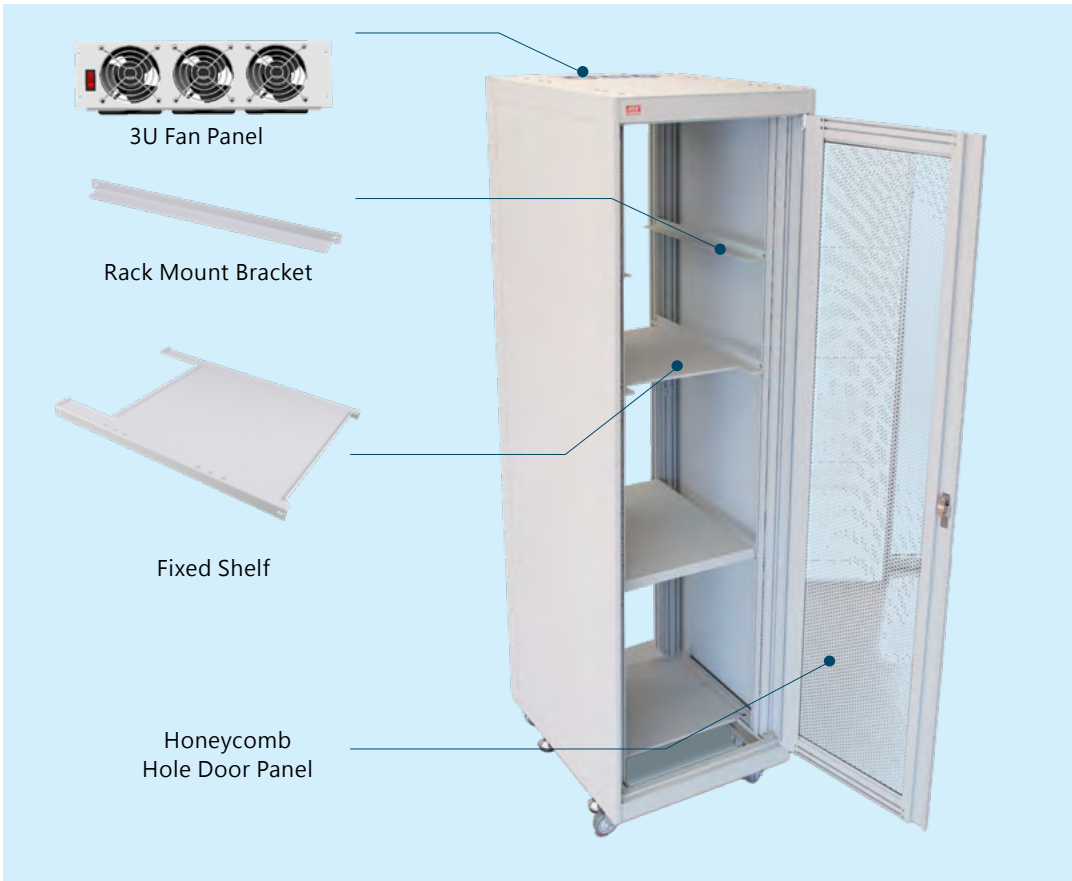

Assembly Diagram

