
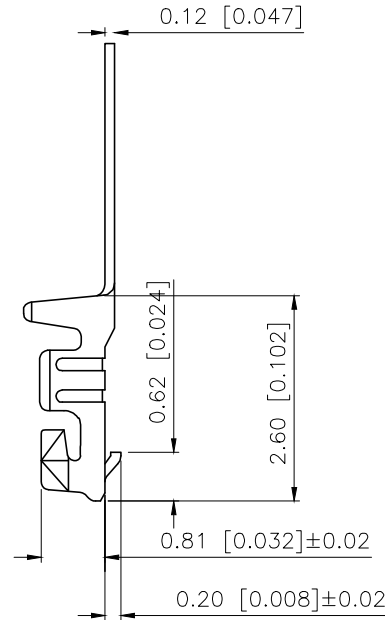


REVISIONS					
REV.	ECN NO.	LOCATION	DESCRIPTION	DATE	DESIGN
A1	N/A		图面升级整理图面	2024.08.27	阿树
A2	N/A		产品工作温度变更	2026.02.25	阿树

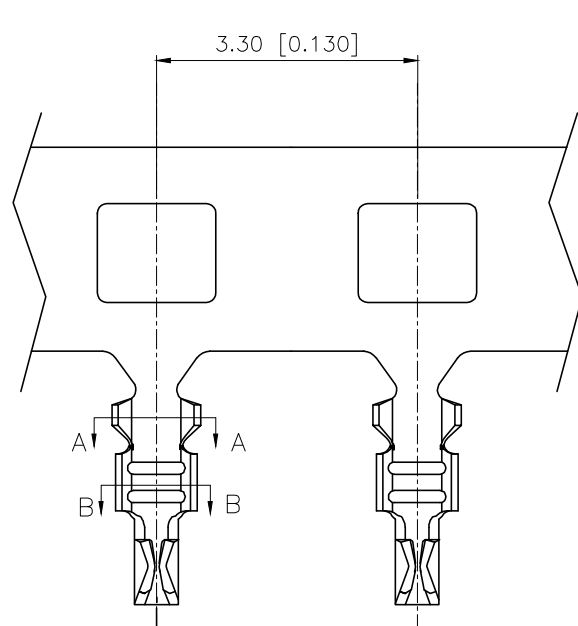



Specifications:

规格:  
Voltage rating: 30V AC/DC  
额定电压: 30V AC/DC  
Current rating: 0.5A AC/DC  
额定电流: 0.5A AC/DC  
Withstanding voltage: 200V AC/minute  
耐压电压: 200V AC/分钟  
Temperature range: -40°C ~ +125°C  
温度范围: -40°C ~ +125°C  
Insulation resistance: ≥100MΩ  
绝缘电阻: ≥100MΩ  
Contact resistance: ≤20mΩ  
接触电阻: ≤20mΩ  
After environment testing: ≤40mΩ  
环境试验后: ≤40mΩ

PART NO.:

X0800 T-P V01  
① ② ③ ④

- ① Series Number
- ② Category: T-terminal
- ③ Material: P-Phosper bronze
- ④ SN: 70-120U" V01 -All Gold Flash

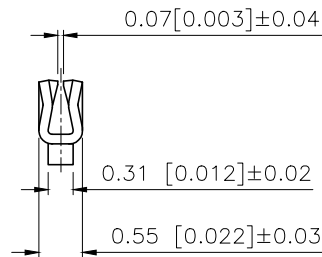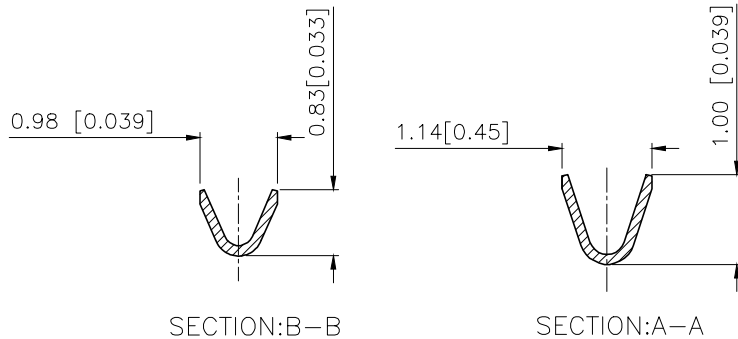

X0800T-PV01	High conductive Brass	AWG#32~36	0.39mm(Max)	Phosphor Bronze	Tin-Plated	X0800W
PART NO	Material	Wire Range	Insulation O.D.	Material (Terminal)	Finish (Terminal)	Suitable XKB Terminal

AuGLAR	±5°
X.	±0.40
X.x	±0.30
X.xx	±0.20
X.xxx	±0.15
UNSPECIFIED TOLERANCES	



DESIGN	阿树	VIEW:		MODEL TYPE: 0.80mm IDC Style Connectors
CHECKED		UNIT:	mm/in	PART NO.: X0800T-PV01
APPROVED		SIZE:	A4	DWG NO.: