

SLIDE SWITCH

碩方精密電子開關

www.Sofng.com

Operation: DIP/插件卧式 3PIN 小型 滑动开关



ITEM NO.: MS-128 (Series)

(L9.0mm × W2.8mm × H2.0mm SLIDE-SWITCH)



表面插装 DIP

側向操作 LATERAL

精密部品 NICETY

可靠 STABILIZE


適合環保 RoHS

Technical parameter




PROJECT	LEVEL	A[better product]	B[average product]
Electrical Properties	Contact Rating	0.3A, 30V DC	
	Initial Contact Resistance	50mΩ max.	
	Insulation Resistance	100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
	Withstand Voltage	300V AC for 1 minute	250 V AC for 1 minute
	There No Load	15,000 Cycles	10,000 Cycles
Durable Performance	Rated Load	12,000 Cycles	8,500 Cycles
	Storage temp.	-25℃~+75℃(Operating Temp:)	
	Operating Force	1.8N. ±0.5N (1N.=100gram-force)	
	Heat Rrsistance	IR Reflow:255℃, 5sec. Manual:350℃, 3sec.	

Material declaration		
No.	NAME	Description
①	拨柄	PA6T (Black)耐高温尼龙
②	盖板	不锈钢 SUS304 t=0.4mm
③	基座	PA6T (Black)耐高温尼龙
④	簧片	磷铜 C5210 G/F
⑤	嵌件	黄铜 C2680(Qsn6.5-01 镀银) t=0.30

CIRCUIT DIAGRAM

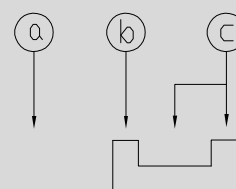


Unit:mm

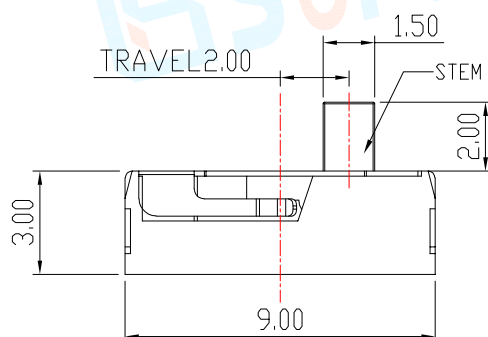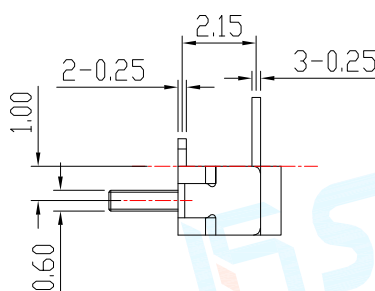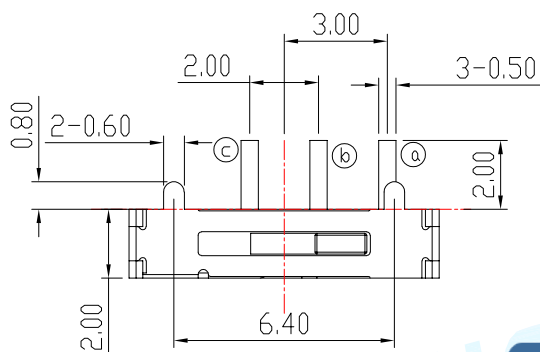

邀您使用(微信)小程序

碩方电子开关&连接器选型手册

手机扫码即可进入...

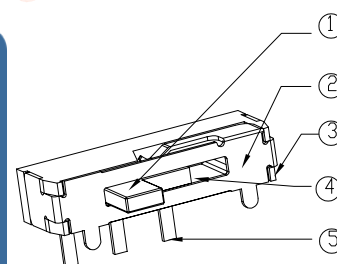

P.C.B LAYOUT

