

Operation: SMT/卧式 小型 检测开关[操作力可定制]



LTEM NO.: TC-623L (Series)

(L5.7×W4.6×H1.85 DETECTOR-SWITCH)

表面貼裝

側向操作

精密部品

NICETY

STABILIZE

適合環保 RoHS


Technical parameter




邀您使用(微信)小程序
碩方电子开关&连接器选型手册
手机扫码即可进入...

PROJECT	LEVEL	A[better product]	B[average product]
Electrical	Contact Rating	50mA, 24V DC	
	Initial Contact Resistance	50mΩ max.	
Properties	Insulation Resistance	100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
	Withstand Voltage	200V AC for 1 minute	100 V AC for 1 minut
Durable Performance	There No Load	100,000 Cycles	80,000 Cycles
	Rated Load	80,000 Cycles	60,000 Cycles
Storage temp.		-20℃~+75℃(Operating Temp:)	
Operating Force		0.5N. (1N.=100gram-force)	
Heat Rrsistance		IR Reflow:235℃,5sec. Manual:350℃,3sec.	



CIRCUIT DIAGRAM

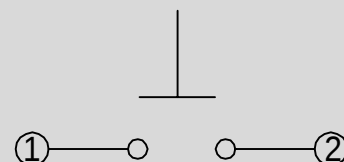

Unit:mm

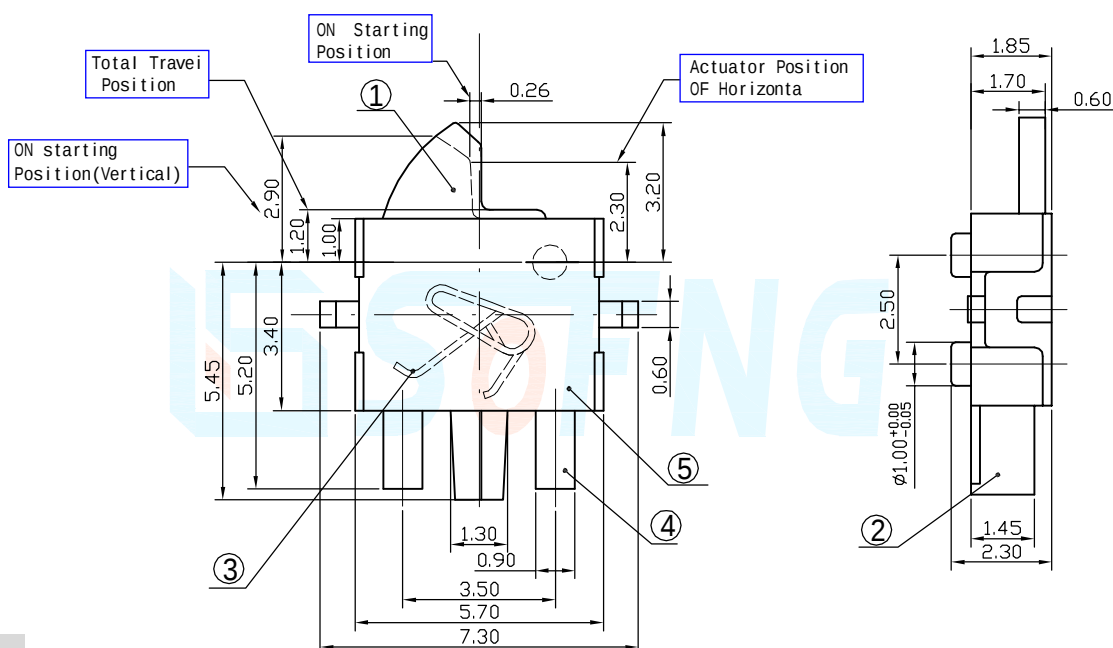

P.C.B LAYOUT

 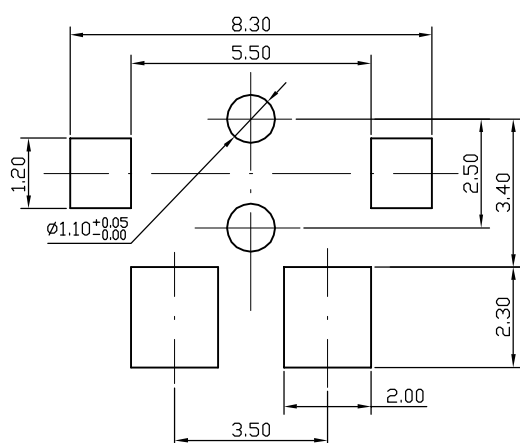

DECIMALS	ANGLES
.X :±0.20	X.° :±1.5°
.XX :±0.10	X.X° :±1.0°
.XXX :±0.05	.XXX° :±0.5°