

Operation:DIP/立插式 中型(单向)柱型柄检测开关[操作力可定制]



ITEM NO.:TC-615D (Series)

(L8.6×W4.3×H11.1mm DETECTOR-SWITCH)

表面插装 DIP

正向操作 DOWN

精密部品
NICETY

STABILIZE

適合環保 RoHS




邀您使用(微信)小程序
碩方电子开关&连接器选型手册
手机扫码即可进入...

Technical parameter



		LEVEL			
PROJECT		A[better product]		B[average product]	
Electrical Properties	Contact Rating	5mA, 12V DC			
	Initial Contact Resistance	50mΩ max.			
	Insulation Resistance	100MΩ min.500V DC	Skey/PD: 100MΩ min.300V DC		
	Withstand Voltage	200V AC for 1 minute	100 V AC for 1 minut		
	There No Load	75,000 Cycles	55,000 Cycles		
Durable Performance	Rated Load	60,000 Cycles	45,000 Cycles		
	Storage temp.	(Operating Temp: -30℃~~+75℃)			
Operating Force		0. 35N. (1N. =100gram-force)			
Operating temperature		IR Reflow:255℃, 5sec. Manual :350℃, 3sec.			

Material declaration		
No.	NAME	Description
1	外壳	PA6T(Gray)耐热塑胶
2	按柄	POM(White)塑胶
3	弹簧	C5191R-H (t=0.15mm)磷青铜
4	基座	PA6T(Gray)耐热塑胶
5	端子	H62 (t=0.20mm)黄铜

Common terminal

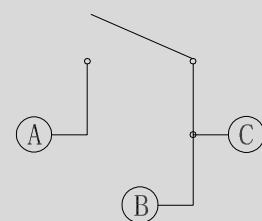

Unit:mm

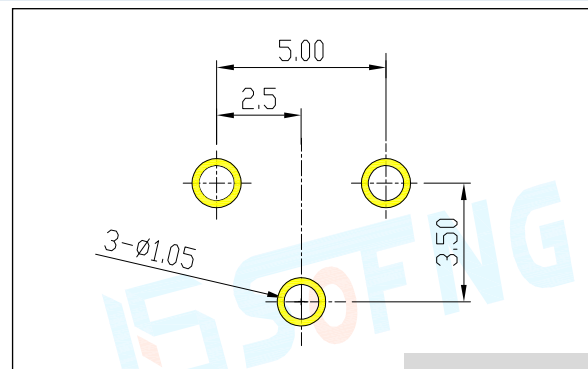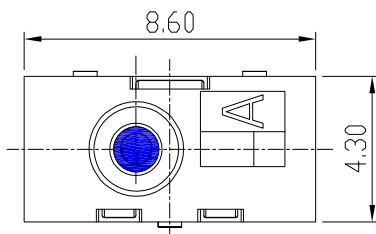

P.C.B LAYOUT

