


Operation: SMT/卧式 小型 左/右检测开关[操作力可定制]

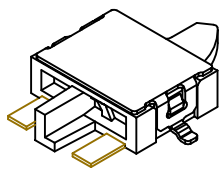

LTEM NO.: TC-623R (Series)

(L5.7×W4.6×H1.85 DETECTOR-SWITCH)



邀您使用(微信)小程序
碩方电子开关&连接器选型手册
手机扫码即可进入...

Technical parameter

PROJECT	LEVEL	A[better product]	B[average product]
Electrical Properties	Contact Rating	50mA, 12V DC	
	Initial Contact Resistance	50mΩ max.	
	Insulation Resistance	100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
	Withstand Voltage	200V AC for 1 minute	100 V AC for 1 minut
	There No Load	75,000 Cycles	55,000 Cycles
Durable Performance	Rated Load	60,000 Cycles	45,000 Cycles
	Storage temp.	-20℃~+75℃(Operating Temp:)	
Operating Force		0.35N. (1N.=100gram-force)	
Operating temperature		IR Reflow:235℃,5sec. Manual:350℃,3sec.	

Material declaration		
No.	NAME	Description
C	上盖	不锈钢 SUS-304 t=0.1
D	拨柄	PA66 (Black)尼龙塑胶
E	弹簧	镀银&磷铜线 ∅0.15
F	基座	PA66 (Black)尼龙塑胶
G	嵌件	镀银&C5191R-H 磷青铜 t=0.15

表面贴装

側向操作


精密部品

NICETY

STABILIZE

適合環保 RoHS

CIRCUIT DIAGRAM

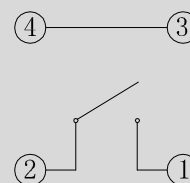

Unit:mm

P.C.B LAYOUT

