

SWITCHES

Operation:DIP/侧向双档拨动开关



LTEM NO.:MS-2235K (Three D)
(L9.0×W3.5×H3.5 SLIDE-SWITCH)



Technical parameter

PROJECT	LEVEL	A[better product]	B[average product]
Electrical Properties	Contact Rating	25mA, 24V DC	
	Initial Contact Resistance	30mΩ max.	50mΩ max.
	Insulation Resistance	100MΩ min.500V DC	Skey/PD: 100MΩ min.300V DC
	Withstand Voltage	500V AC for 1 minute	350 V AC for 1 minut
	There No Load	15,000 Cycles	10,000 Cycles
Durable Performance	Rated Load	12,000 Cycles	8,500 Cycles
	Storage temp.	-30℃~+85℃(Operating Temp:)	

表面插装 DIP





侧向操作 LATERAL

精密部品 NICETY

可靠 STABILIZE

適合環保 RoHS

Unit:mm

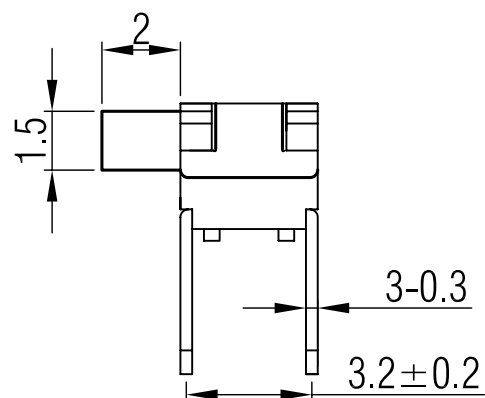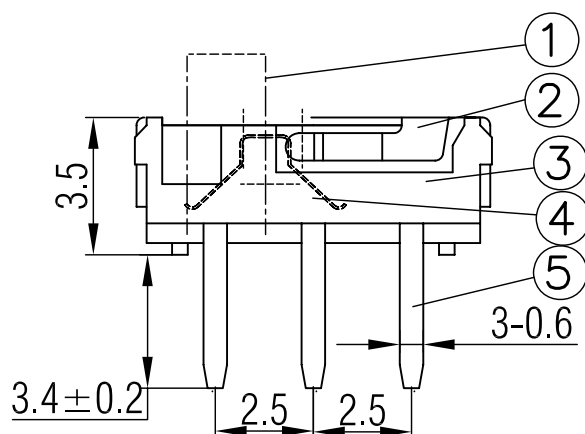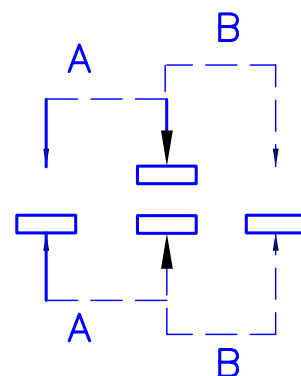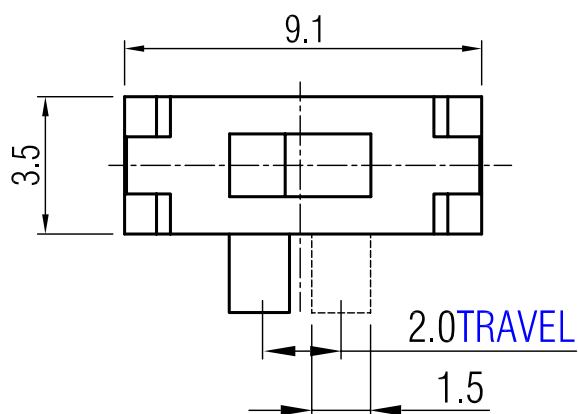

Operating Force

Inward

2. 5N(100grams) $\pm$ 50gf


Exiting

2. 5N(100grams) $\pm$ 50gf

邀您使用(微信)小程序

碩方电子开关&连接器选型手册

手机扫码即可进入...

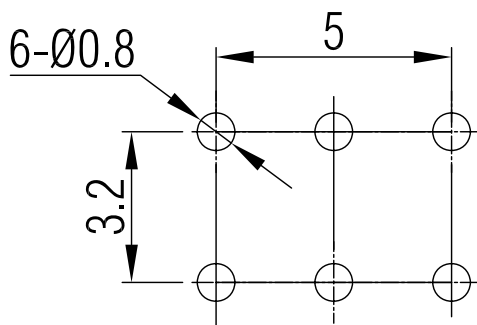

Pin Definition



Material declaration

No.	NAME	Type	Description
① A	拨柄	1	PA66 (Black)热塑性
② B	盖板	1	不锈钢 SUS304 t=0.2mm
③ C	基座	1	PA66 (Black)热塑性
④ D	簧片	1	磷铜 C5210 G/F
⑤ E	嵌件	6	黄铜 C2680(Qsn6.5-01 镀银) t=0.2



本品不屬於危害性廢棄物,須丟棄時可以委託
回收商予以回收再生處理。

Products do not belong to •

注記 NOTICE

- 碩方公司擁有最終解釋權; The company reserves the right of final interpretation;
- 文件禁止外洩、轉載; Leaked and reproduced prohibited;
- 未經授權修改無效。Modify is invalid.

運送時本產品不要直接與水、酸鹼性化學物質接觸,或放置於含有以上氣體環境中,並且需要注意會有滑落、側翻的危險發生; 運輸過程中不能有碰撞或者擠壓,須保證溫度與濕度適中 [常溫 25℃,濕度在 50℃以內],不可導致材料變形或氧化。