

SLIDE SWITCH

Operation: SMT/立贴式中小型 10PIN 四挡位外贴脚滑动开关 [柄长可定制]



ITEM NO.: MS-252 (Series)

(L15.0mm×W3.5mm×H5.50mm SLIDE-SWITCH)

表面贴装 SMT

正向操作 DOWN

精密部品 NICETY

可靠 STABILIZE


適合環保 RoHS

Technical parameter





PROJECT	LEVEL	A[better product]	B[average product]
Electrical Properties	Contact Rating	0.5A, 30V DC	
	Initial Contact Resistance	50mΩ max.	
	Insulation Resistance	100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
Durable Performance	Withstand Voltage	300V AC for 1 minute	250 V AC for 1 minut
	There No Load	15,000 Cycles	10,000 Cycles
	Rated Load	12,000 Cycles	8,500 Cycles
	Storage temp.	-25℃~+75℃(Operating Temp:)	
	Operating Force	2.6N. (1N.=100gram-force) ±0.5N	
	Heat Rsrstence	IR Reflow:255℃, 5sec. Manual:350℃, 3sec.	

Material declaration		
No.	NAME	Description
1	拨柄	PA46 耐热尼龙塑料
2	盖板	C5191R-H 磷铜[镀银]
3	基座	LCP 30%G/F (Black)耐热塑胶
4	弹片	Beryllium bronze 铍青铜[单面镀银]
5	嵌件	C5191R-H 磷铜[镀银]

CIRCUIT DIAGRAM

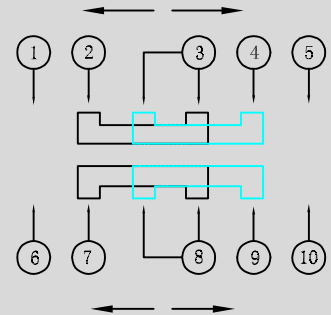

Unit:mm

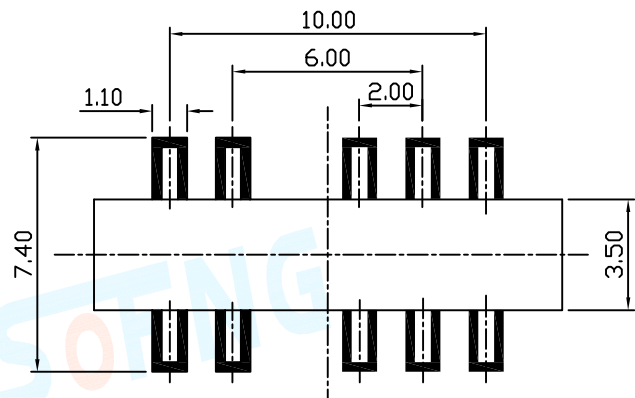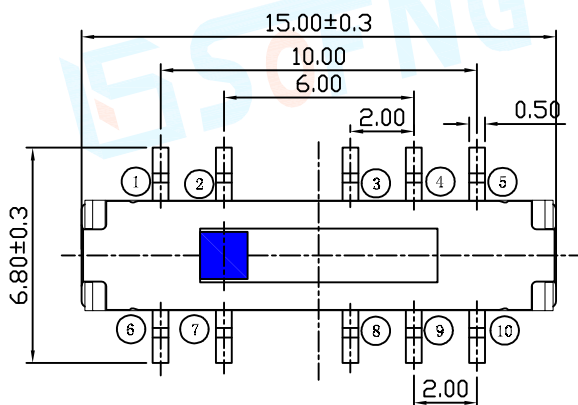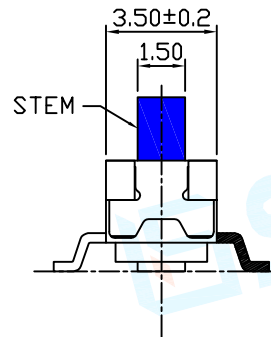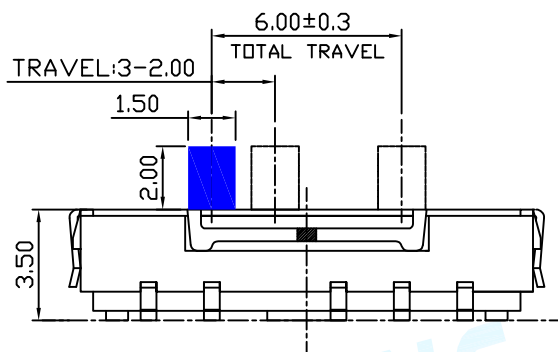

P.C.B LAYOUT

