

SLIDE SWITCH

碩方精密電子開關

www.Sofng.com

Operation:DIP/卧插式 中型 3PIN 二挡 滑动开关 [柄长可定制]



ITEM NO.:MS-210D (Series)

(L10.1mm×W5.0mm×H3.0mm SLIDE-SWITCH)

表面插装 DIP

側向操作 LATERAL

精密部品 NICETY

可靠 STABILIZE

適合環保 RoHS




邀您使用(微信)小程序
碩方电子开关&连接器选型手册
手机扫码即可进入...



Technical parameter

		LEVEL	
PROJECT		A[better product]	B[average product]
Electrical Properties	Contact Rating	0.3A, 30V DC	
	Initial Contact Resistance	50mΩ max.	
	Insulation Resistance	100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
	Withstand Voltage	300V AC for 1 minute	250 V AC for 1 minute
	There No Load	15,000 Cycles	10,000 Cycles
Durable Performance	Rated Load	12,000 Cycles	8,500 Cycles
	Storage temp.	-25℃~+75℃(Operating Temp:)	
Operating Force		2.6N. (1N.=100gram-force) ±0.5N	
Heat Rrsistance		IR Reflow:255℃, 5sec. Manual:350℃, 3sec.	

CIRCUIT DIAGRAM

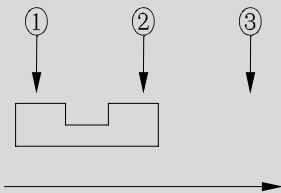

Unit:mm

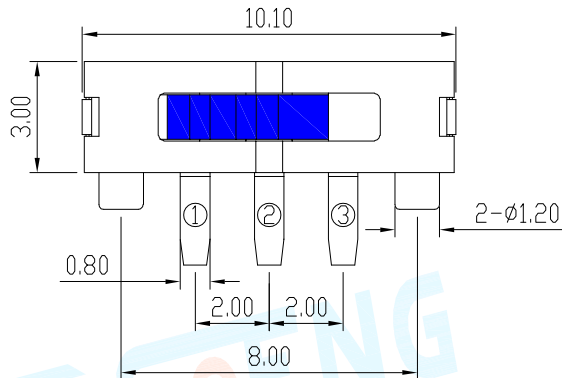 

P.C.B LAYOUT

