

Operation: SMT/贴片卧式 3PIN 小型 滑动开关



LTEM NO.: MS-127F (Series)

(L8.8mm × W3.0mm × H2.0mm SLIDE-SWITCH)

 
表面貼裝 SMT

側向操作 LATERAL

精密部品 NICETY

可靠 STABILIZE

適合環保 RoHS




邀您使用(微信)小程序
碩方电子开关&连接器选型手册
手机扫码即可进入...

Technical parameter

		LEVEL			
PROJECT		A[better product]		B[average product]	
Electrical Properties	Contact Rating	0.3A, 30V DC			
	Initial Contact Resistance	50mΩ max.			
	Insulation Resistance	100MΩ min.500V DC	Skey/PD: 100MΩ min.300V DC		
	Withstand Voltage	300V AC for 1 minute	250 V AC for 1 minute		
	There No Load	15,000 Cycles	10,000 Cycles		
Durable Performance	Rated Load	12,000 Cycles	8,500 Cycles		
	Storage temp.	-25℃~+75℃(Operating Temp:)			
Operating Force		1. 8N. ±0. 5N (1N. =100gram-force)			
Heat Rrsistance		IR Reflow:255℃, 5sec. Manual:350℃, 3sec.			

CIRCUIT DIAGRAM

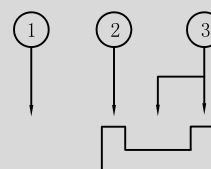

Unit:mm

