

Operation: SMT/卧贴式 小型(左/右)检测开关[操作力可定制]



ITEM NO.: TC-620U (Series)

(14.0×W5.0×H1.6mm DETECTOR-SWITCH)

表面贴装 SMT

側向操作

精密部品
NICETY

STABILIZE


適合環保 RoHS

Technical parameter




PROJECT	LEVEL	A[better product]	B[average product]
Electrical Properties	Contact Rating	50mA, 12V DC	
	Initial Contact Resistance	50mΩ max.	
	Insulation Resistance	100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
	Withstand Voltage	200V AC for 1 minute	100 V AC for 1 minute
	There No Load	75,000 Cycles	55,000 Cycles
	Rated Load	60,000 Cycles	45,000 Cycles
	Storage temp.	(Operating Temp: -40℃~+85℃)	
	Operating Force	0.35N. (1N.=100gram-force)	
	Operating temperature	IR Reflow:255℃, 5sec. Manual:350℃, 3sec.	

Material declaration		
No.	NAME	Description
C	按柄	PA6T(Gray)耐热塑胶
D	横片	PA6T(Gray)耐热塑胶
E	基座	PA6T(Gray)耐热塑胶
F	外壳	H62 Y 黄铜 t=0.25mm 镀银
G	端子	QSn6.5-01 (t=0.20mm)锡青铜
H	弹簧	不锈钢 SUS304 【t=0.1mm】




Common terminal

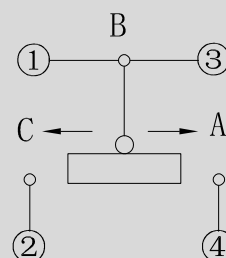

Unit:mm

 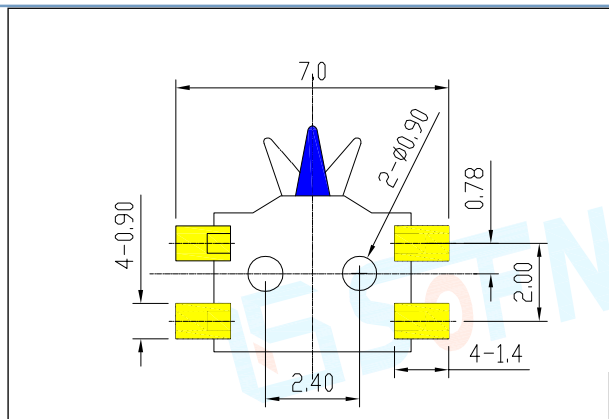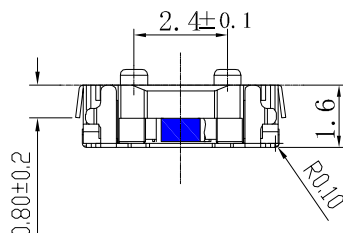

P.C.B LAYOUT

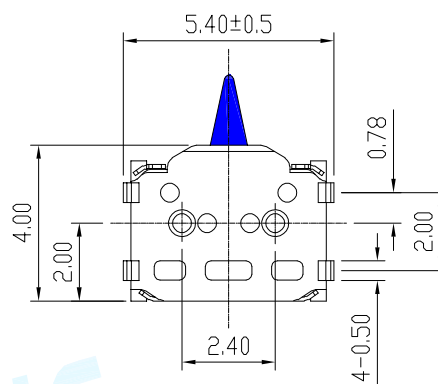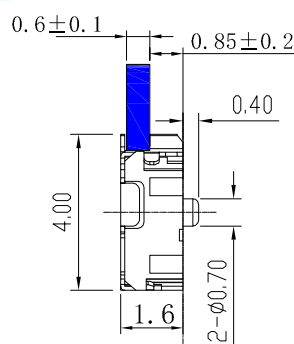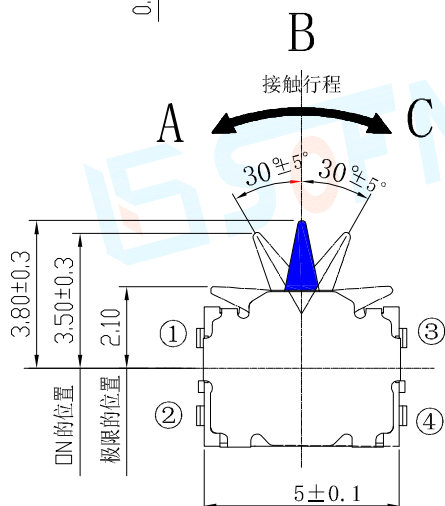

CODE TABLE (ON)

ANGLE	85°	0°	85°
TERMINAL	C	B	A
	(30°)		(30°)
②			
① ③			
④			

推荐锡膏厚度 0.12mm

