

Operation: SMT/卧贴式 中型(二向)扇型柄检测开关[操作力可定制]



ITEM NO.: TC-661 (Series)

(L6.35×W4.9×H2.55mm DETECTOR-SWITCH)

表面贴装 SMT

側向操作 LATERAL

精密部品 NICETY

STABILIZE

適合環保 RoHS


Technical parameter

PROJECT	LEVEL	A[better product]	B[average product]
Electrical Properties	Contact Rating	0.1A, 12V DC	
	Initial Contact Resistance	50mΩ max.	
	Insulation Resistance	100MΩ min.500V DC	Skey/PD: 100MΩ min.300V DC
	Withstand Voltage	200V AC for 1 minute	100 V AC for 1 minut
Durable Performance	There No Load	75,000 Cycles	55,000 Cycles
	Rated Load	60,000 Cycles	45,000 Cycles
Storage temp.		(Operating Temp: -30℃~+75℃)	
Operating Force		0.35N. (1N.=100gram-force)	
Operating temperature		IR Reflow:255℃, 5sec. Manual:350℃, 3sec.	


Material declaration

No.	NAME	Description
1	按柄	PA6T(Gray)耐热塑胶
2	弹片	C5191R-H (t=0.15mm)磷青铜
3	基座	PA6T(Gray)耐热塑胶
4	端子	H62 (t=0.20mm)黄铜



Common terminal

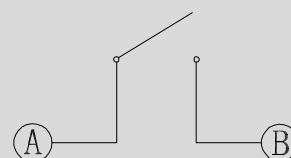

Unit:mm

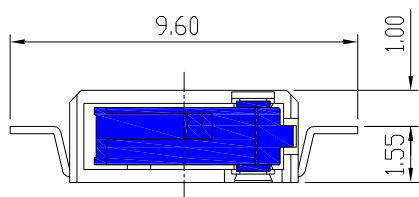

动作方向

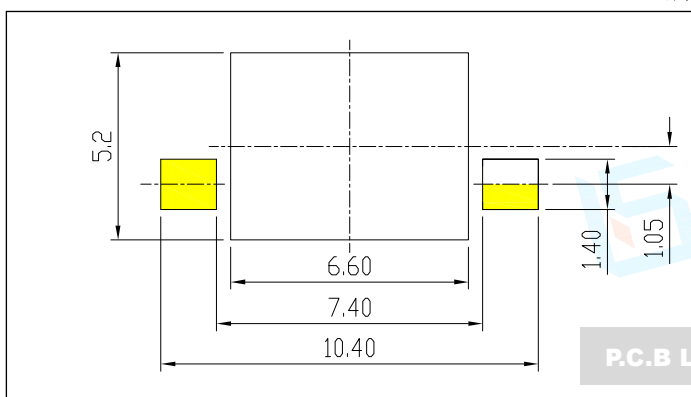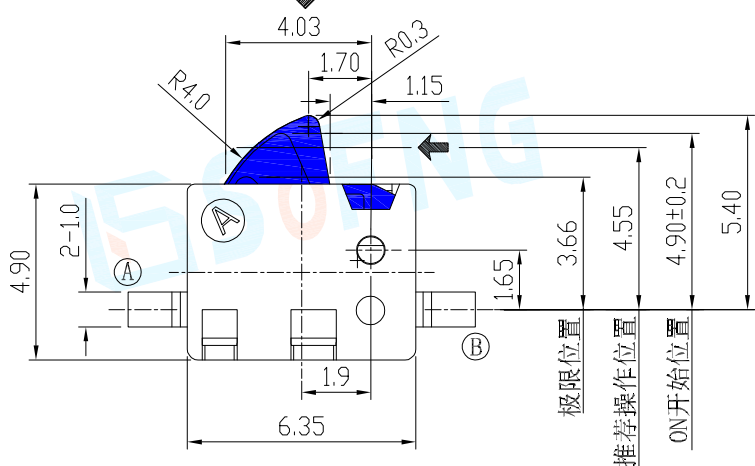

P.C.B LAYOUT



邀您使用(微信)小程序

碩方电子开关&连接器选型手册

手机扫码即可进入...

