


Operation:DIP/push



LTEM NO.:TC-BJ01 (Three D)
(12.6×5.8 DETECTOR-SWITCH)

Unit:mm

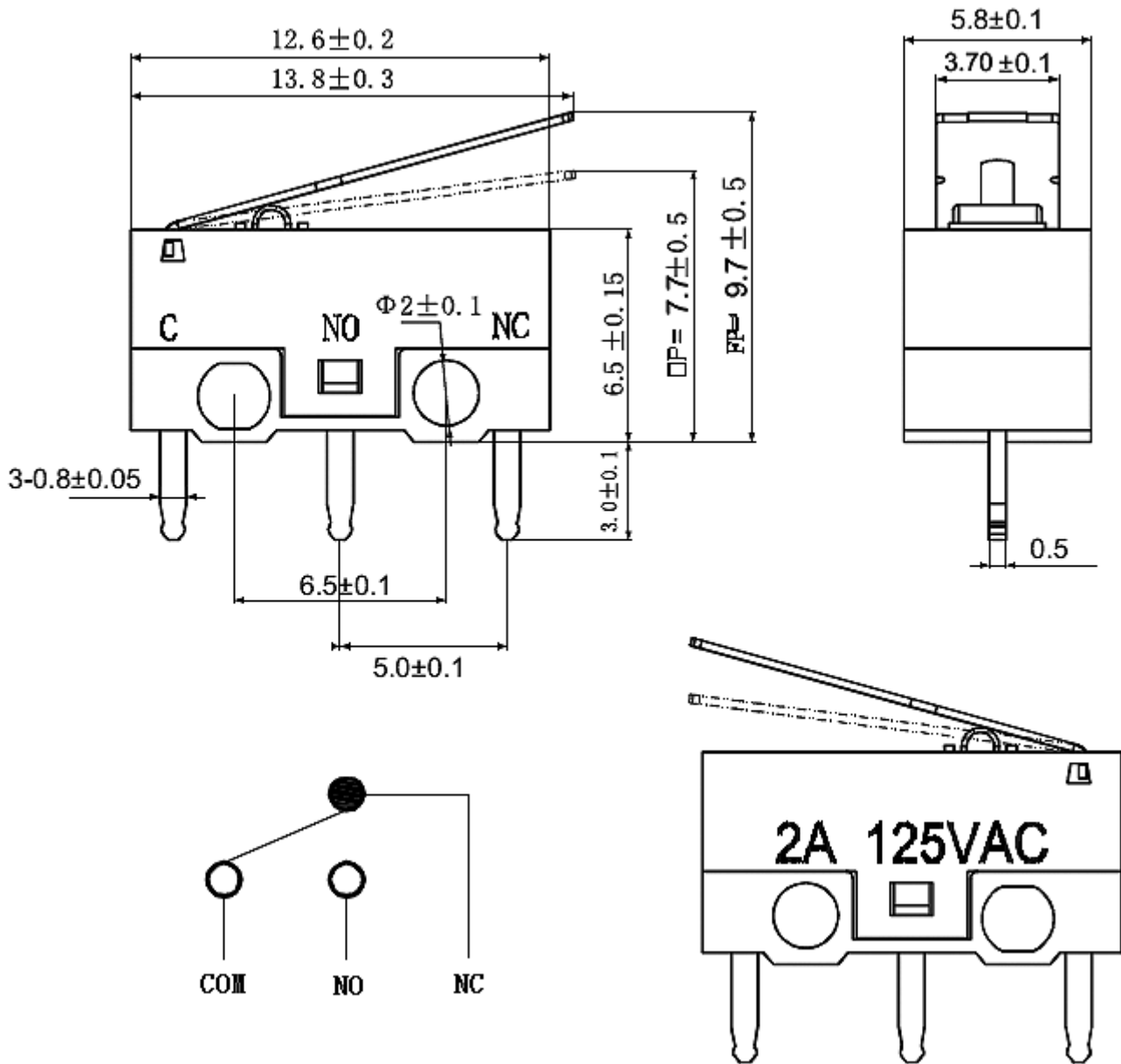

Technical parameter

PROJECT		LEVEL	A[better product]	B[average product]	C[low product]
Electrical Properties	Initial Contact Resistance		30mΩ max.	30mΩ max.	no data!
	Contact Resistance		100MΩ min.100V DC Skey/PD: 50MΩ min.100V DC		
	Withstand Voltage		300V AC for 1min	250 V AC for 1min	
Durable Performance		There No Load	500,000 Cycles	400,000 Cycles	no data!
		Rated Load	400,000 Cycles 50mΩ max.	300,000 Cycles 30mΩ max.	no data!
Insertion Force			4.0Kgf MAX (Springback:)		

表面插装 DIP

正向導入 LATERAL

精密部品 NICETY

可靠 STABILIZE


適合環保 RoHS

CIRCUIT BOARD SIZE

(Vertical view)



邀您使用(微信)小程序
 碩方电子开关&连接器选型手册
 手机扫码即可进入...

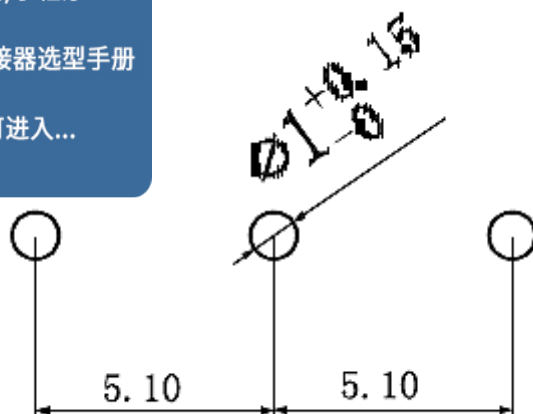

项目 \ 等级		A 级[产品]	B 级[产品]	C 级[产品]
机械性能	端子强度	3N for 1 min.	2N for 1min.	
	操作强度	工作方向	1. 00N (100grams) $\pm$ 20gf	
		拉引方向	0. 85N [(40grams) $\pm$ 10gf]	

PIN Assignment

Material declaration

No.	NAME	Type	Description
① A	拨柄	1	POM (Black)热塑性
② B	基座	1	PAHTN (Black)热塑性
③ C	盖板	1	PA66 (Black)热塑性
④ D	嵌件	1	锡青铜(Qsn6.5-01 镀银) t-0.2
⑤ E	簧片	1	不锈钢 SUS304 外径 1.2X6.4
⑥ F	弹簧	1	不锈钢 直径=0.15

本品不屬於危害性廢棄物,須丟棄時可以委託回收商予以回收再生處理。Products do not belong to hazardous waste, When waste can recycling processing

運送時本產品不要直接與水、酸鹼性化學物質接觸,或放置於含有以上氣體環境中,並且需要注意會有滑落、側翻的危險發生;運輸過程中不能有碰撞或者擠壓,須保證溫度與濕度適中[常溫 25℃,濕度在 50℃以內],不可導致材料變形或氧化。

注記 NOTICE

- 碩方電子公司擁有最終解釋權; The company reserves the right of final interpretation;
- 文件禁止外洩、轉載; Leaked and reproduced prohibited;
- 未經授權修改無效。Modify is invalid.