

Operation: SMT/立贴式 小型(左/右)检测开关[操作力可定制]



ITEM NO.: TC-640S (Series)

(L7.5×W3.0×H8.55 DETECTOR-SWITCH)

表面贴装 SMT

正向操作

精密部品
NICETY

STABILIZE

適合環保 RoHS


Technical parameter

PROJECT	LEVEL	A[better product]	B[average product]
Electrical Properties	Contact Rating	50mA, 12V DC	
	Initial Contact Resistance	50mΩ max.	
	Insulation Resistance	100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
	Withstand Voltage	200V AC for 1 minute	100 V AC for 1 minut
Durable Performance	There No Load	75,000 Cycles	55,000 Cycles
	Rated Load	60,000 Cycles	45,000 Cycles
Storage temp.		(Operating Temp: -40℃~+85℃)	
Operating Force		0.35N. (1N.=100gram-force)	
Operating temperature		IR Reflow:255℃,5sec. Manual:350℃,3sec.	







Material declaration

No.	NAME	Description
C	按柄	PA6T(Gray)耐热塑胶
D	横片	PA6T(Gray)耐热塑胶
E	基座	PA6T(Gray)耐热塑胶
F	外壳	H62 Y 黄铜 t=0.25mm 镀银
G	端子	QSn6.5-01 (t=0.20mm)锡青铜
H	弹簧	不锈钢 SUS304 【t=0.1mm】

Common terminal

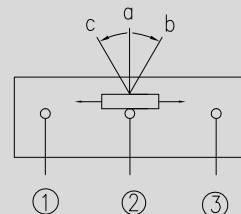

Unit:mm

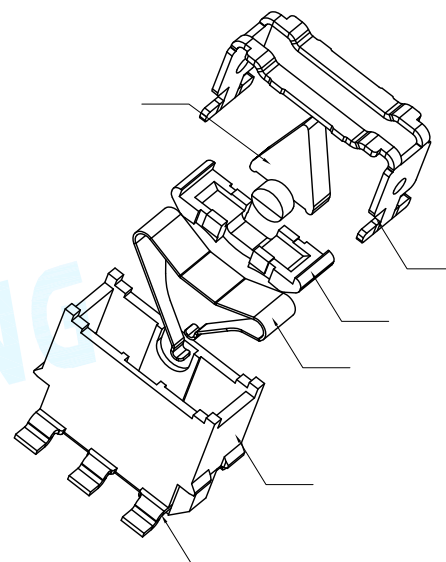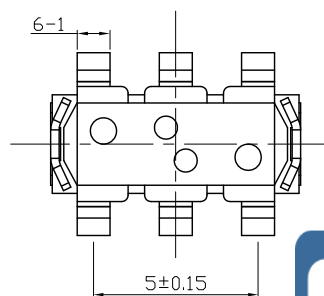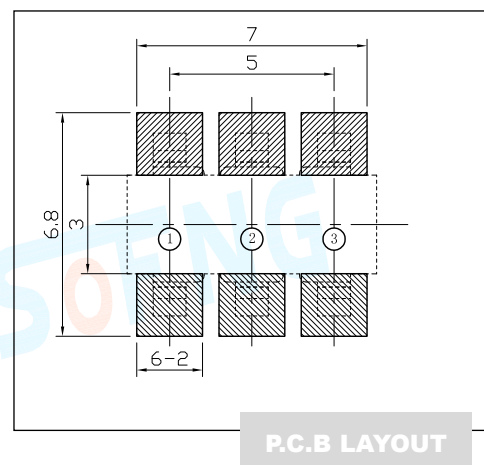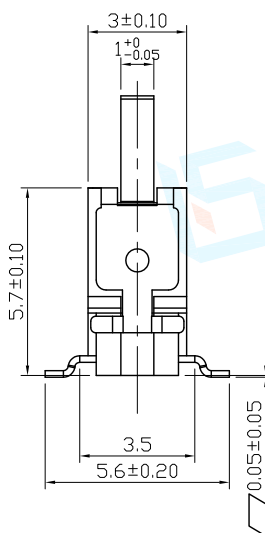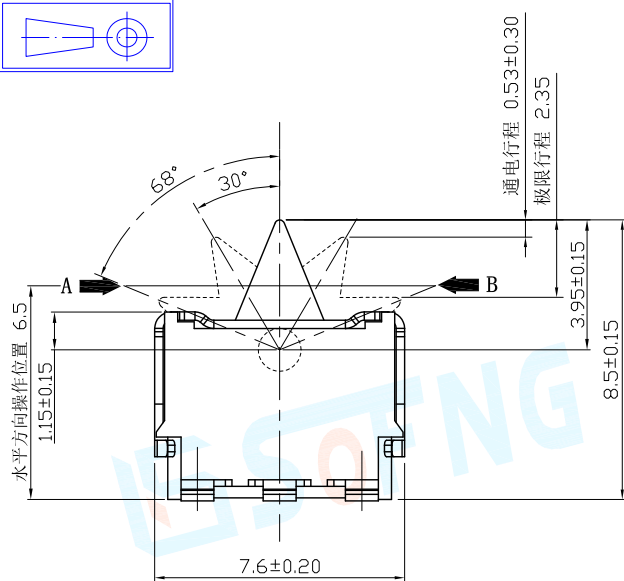 

DECIMALS	ANGLES
.X :±0.20	X.° :±1.5°
.XX :±0.10	X.X° :±1.0°
.XXX :±0.05	.XXX° :±0.5°



邀您使用(微信)小程序
碩方电子开关&连接器选型手册
手机扫码即可进入...