

Operation: SMT/卧贴式 3PIN 小型自复位滑动开关



LTEM NO.: MS-127B

(Series)

(L8.8mm × W3.0mm × H2.0mm SLIDE-SWITCH)

表面贴装 SMT

側向操作 LATERAL

精密部品 NICETY

可靠 STABILIZE


適合環保 RoHS

Technical parameter




PROJECT		LEVEL	A[better product]	B[average product]
Electrical Properties	Contact Rating		0.3A, 30V DC	
	Initial Contact Resistance		50mΩ max.	
	Insulation Resistance		100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
Durable Performance	Withstand Voltage		300V AC for 1 minute	250 V AC for 1 minut
	There No Load		15,000 Cycles	10,000 Cycles
	Rated Load		12,000 Cycles	8,500 Cycles
	Storage temp.		-25℃~+75℃(Operating Temp:)	
	Operating Force		1. 8N. ±0. 5N (1N.=100gram-force)	
	Heat Rrsistance		IR Reflow:255℃, 5sec. Manual:350℃, 3sec.	

Material declaration		
No.	NAME	Description
A	拨柄	PA6T (Black)耐高温尼龙
B	基座	PA6T (Black)耐高温尼龙
C	盖板	不锈钢 SUS304 t=0.4mm
D	簧片	磷铜 C5210 G/F
E	嵌件	黄铜 C2680(Qsn6.5-01 镀银) t=0.30
F	弹簧	不锈钢 SUS304



CIRCUIT DIAGRAM

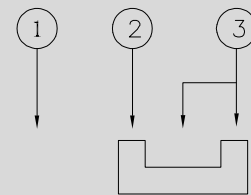

Unit:mm

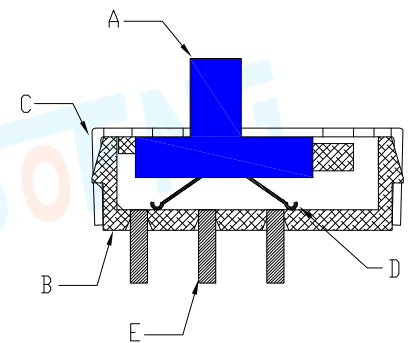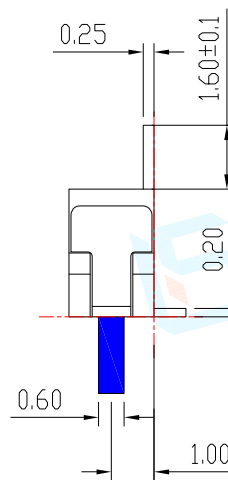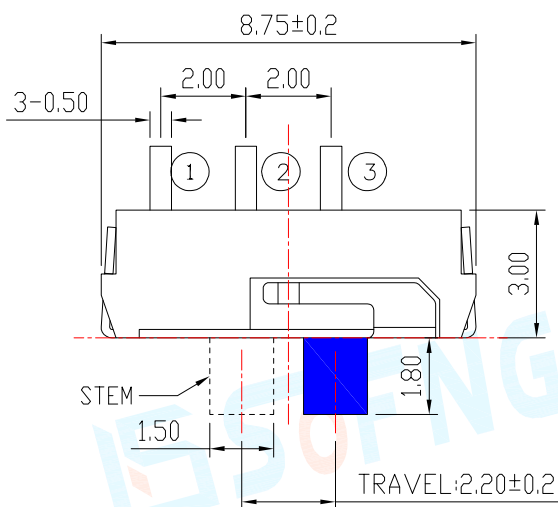

P.C.B LAYOUT

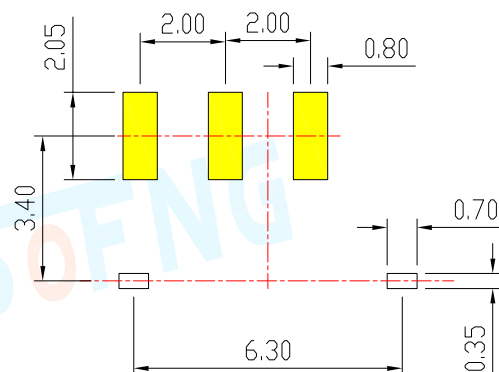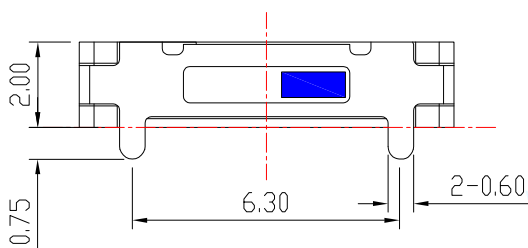

推荐锡膏厚度

0.12mm

