

Operation: DIP/立插式 中型 单向检测开关[操作力可定制]

RoHS Compliant

ITEM NO.: TC-631 (Series)

(L10.0×W4.8×H7.0 DETECTOR-SWITCH)

表面插装

正向操作

精密部品 NICETY

STABILIZE

適合環保 RoHS




邀您使用(微信)小程序
碩方电子开关&连接器选型手册
手机扫码即可进入...



Technical parameter

		LEVEL	
PROJECT		A[better product]	B[average product]
Electrical Properties	Contact Rating	50mA, 12V DC	
	Initial Contact Resistance	50mΩ max.	
	Insulation Resistance	100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
	Withstand Voltage	200V AC for 1 minute	100 V AC for 1 minut
	There No Load	75,000 Cycles	55,000 Cycles
Durable Performance	Rated Load	60,000 Cycles	45,000 Cycles
	Storage temp.	(Operating Temp: -30℃~+75℃)	
Operating Force		0.35N. (1N.=100gram-force)	
Operating temperature		IR Reflow:255℃,5sec. Manual:350℃,3sec.	

Common terminal

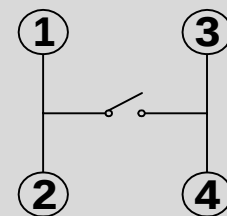

Unit:mm

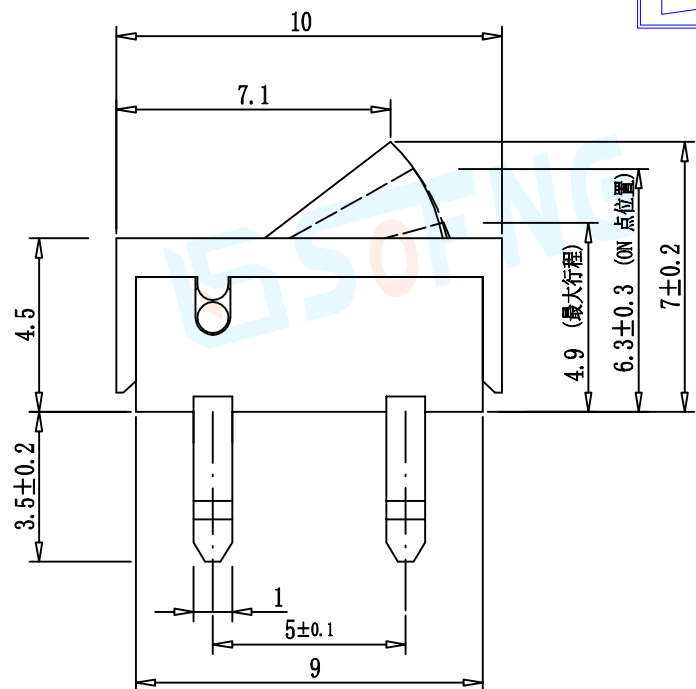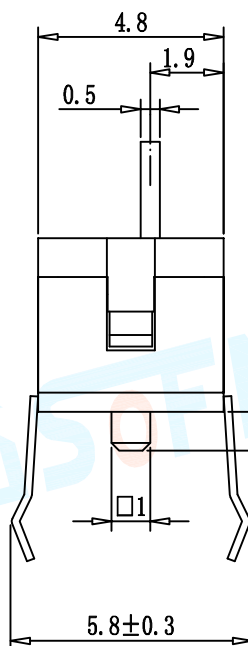

P.C.B LAYOUT

