
 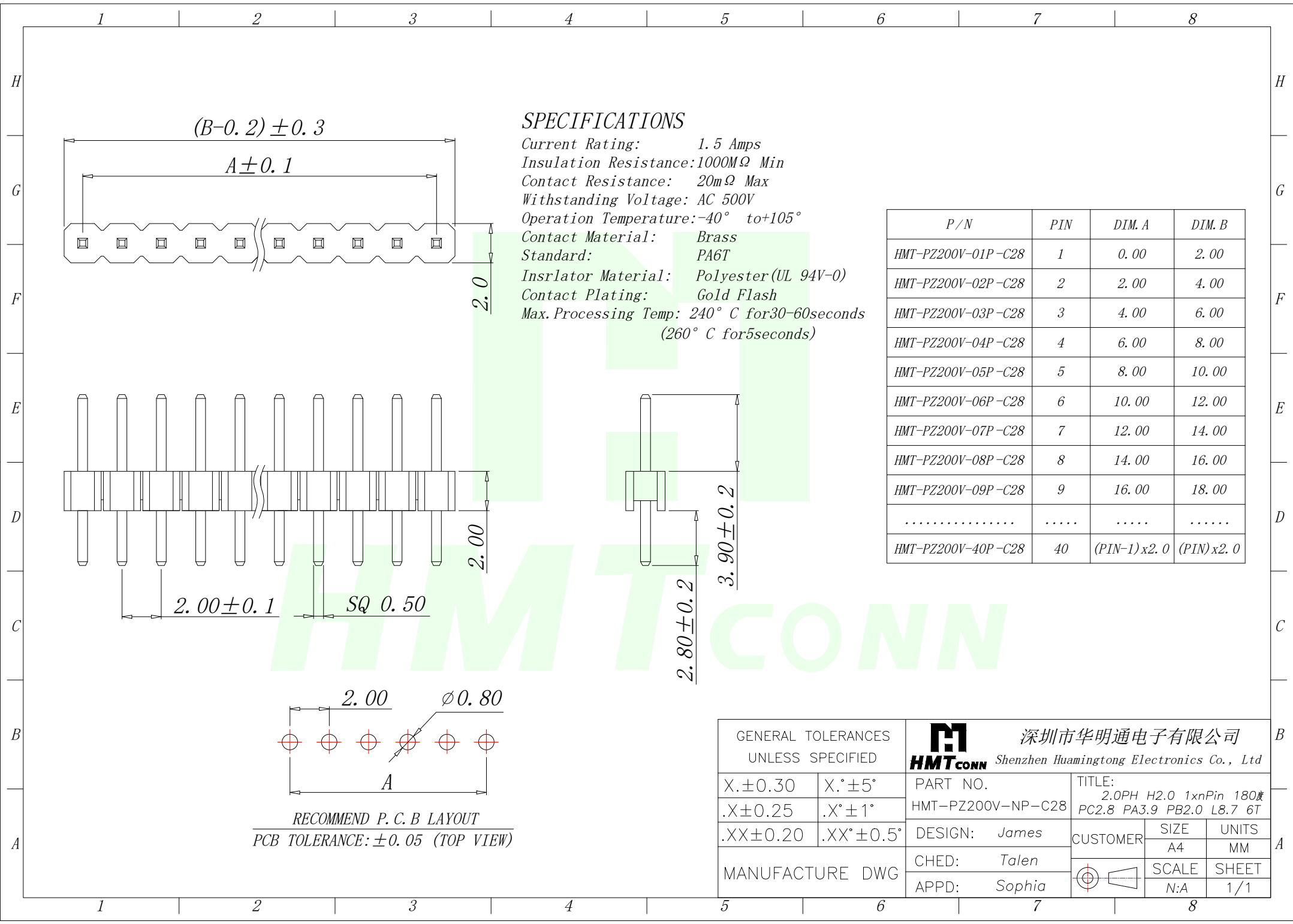




SPECIFICATIONS

Current Rating: 1.5 Amps
Insulation Resistance: 1000M Ω Min
Contact Resistance: 20m Ω Max
Withstanding Voltage: AC 500V
Operation Temperature: -40° to +105°
Contact Material: Brass
Standard: PA6T
Insulator Material: Polyester (UL 94V-0)
Contact Plating: Gold Flash
Max. Processing Temp: 240° C for 30-60 seconds
(260° C for 5 seconds)

P / N	PIN	DIM. A	DIM. B
HMT-PZ200V-01P-C28	1	0.00	2.00
HMT-PZ200V-02P-C28	2	2.00	4.00
HMT-PZ200V-03P-C28	3	4.00	6.00
HMT-PZ200V-04P-C28	4	6.00	8.00
HMT-PZ200V-05P-C28	5	8.00	10.00
HMT-PZ200V-06P-C28	6	10.00	12.00
HMT-PZ200V-07P-C28	7	12.00	14.00
HMT-PZ200V-08P-C28	8	14.00	16.00
HMT-PZ200V-09P-C28	9	16.00	18.00
.....			
HMT-PZ200V-40P-C28	40	(PIN-1) x 2.0	(PIN) x 2.0

GENERAL TOLERANCES UNLESS SPECIFIED		 深圳市华明通电子有限公司 HMTCONN Shenzhen Huamingtong Electronics Co., Ltd		
X. ± 0.30	X.° $\pm 5^\circ$	PART NO.	TITLE:	
.X ± 0.25	.X° $\pm 1^\circ$	HMT-PZ200V-NP-C28	2.0PH H2.0 1xnPin 180° PC2.8 PA3.9 PB2.0 L8.7 6T	
.XX ± 0.20	.XX° $\pm 0.5^\circ$	DESIGN: James	CUSTOMER	SIZE
MANUFACTURE DWG		CHED: Talen		UNITS
		APPD: Sophia		SCALE
				SHEET
				N:A 1/1