
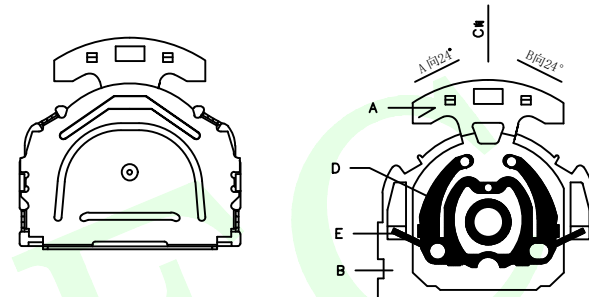


RoHS Compliant

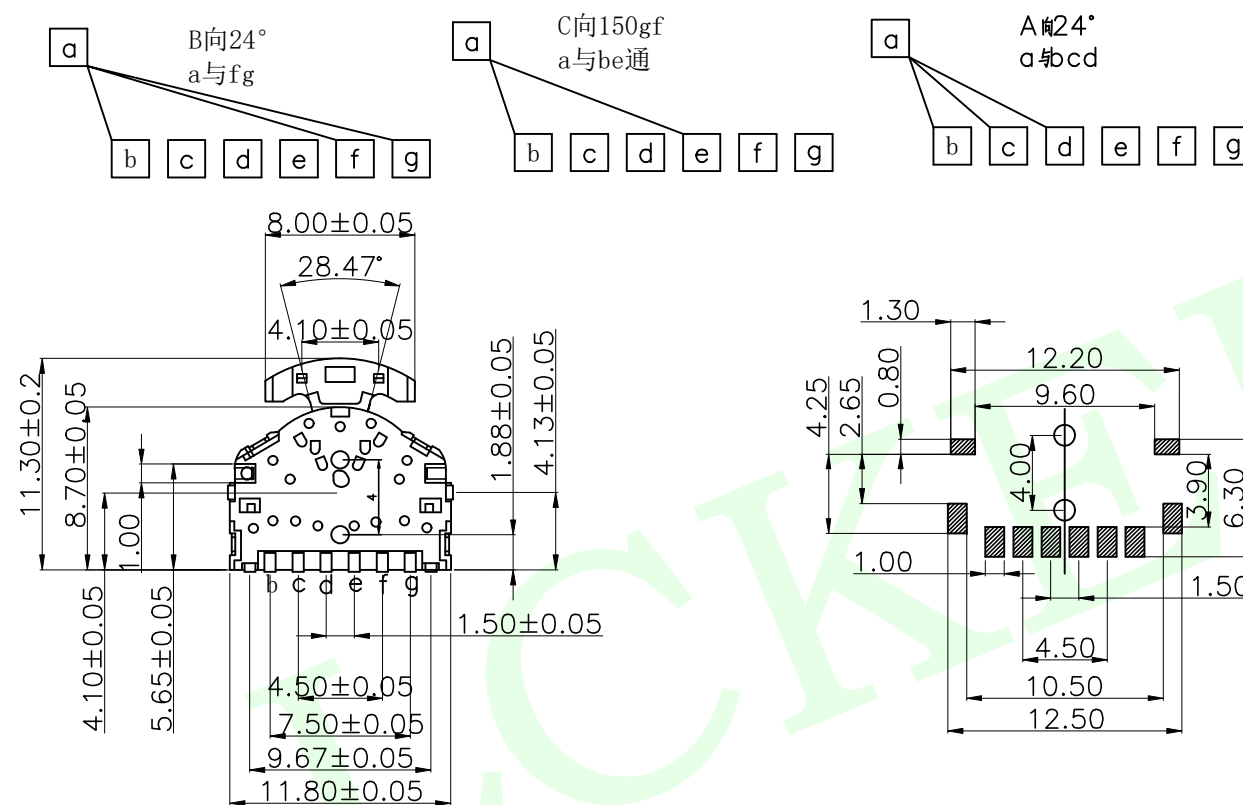

LCK-TG 002B-G1

连晟欣
LCK

产品类别
TG: 波轮开关
TK: 五向开关

产品流水料号识别码

电镀规格
G1: 1U
G3: 3U
(以此类推)

项 目	标 准
电气性能	额定电流 Rated Current: 0.1A MAX
	额定电压 Rated voltage: DC 12V
	接触电阻 Contact resistance: ≤100mΩ
	绝缘电阻 Insulation Resistance: ≥100MΩ
	耐压强度 Compressive strength: AC110V 50Hz/1 min
机械性能	操作力度 Operating force: 2-100±50gf 250gf±50gf
	机械寿命 Mechanical life: 10,000 cycles Min
	操作行程 Operation Stroke: 0.85+0.2mm
环境性能	温度范围 Temperature Range: -30°C ~ +85°C

NO.	零件名称 Part Name	QTY	材料 Material	镀涂 Plating coating	颜色 colour	备注 Remarks
E	弹簧	1	SUS301	/	银白色	
D	接触簧片	1	复银铜	/	银白色	
C	盖板	1	SUS301	整体清洗	银白色	
B	底座/基座	1	PA46	/	黑色	
A	桃心	1	PA46	/	黑色	

MEASURE POINT: QUADRANT POINT (QP)		<p>联晟欣连接器 (深圳) 有限公司 Lianshengxin Connector (Shenzhen) Co., Ltd</p>				
TANGENCY POINT (TP)						
INTERSECTION POINT (IP)						
UNLESS OTHERWISE SPECIFIED, TOLERANCE:		DESIGN	Andy	DATE	2014.12.24	TITLE:
X.	±0.25	CHECKED		DATE		Wheel switch series
X.x	±0.20	APPROVED		DATE		
X.xx	±0.15	PART NO: LCK-TG002B-G1		REV: 04	SCALE: 1:1	UNIT: mm
ANGULAR	±3°	DRAWING NO:		SIZE: A4	SHEET: 1/1	UNIT: mm