
 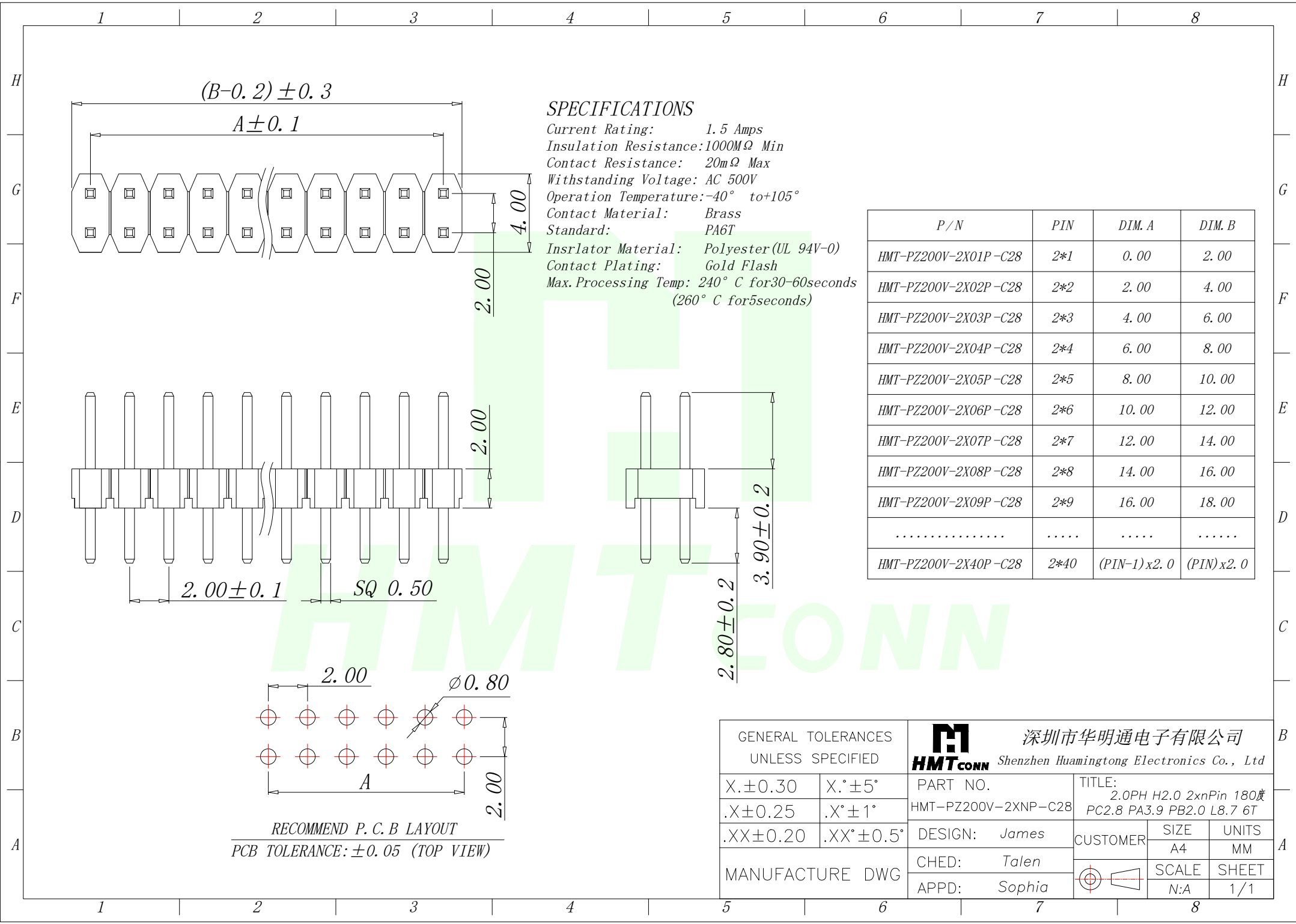




SPECIFICATIONS

Current Rating: 1.5 Amps
Insulation Resistance: 1000MΩ Min
Contact Resistance: 20mΩ Max
Withstanding Voltage: AC 500V
Operation Temperature: -40° to +105°
Contact Material: Brass
Standard: PA6T
Insulator Material: Polyester (UL 94V-0)
Contact Plating: Gold Flash
Max. Processing Temp: 240° C for 30-60 seconds
(260° C for 5 seconds)

P / N	PIN	DIM. A	DIM. B
HMT-PZ200V-2X01P-C28	2*1	0.00	2.00
HMT-PZ200V-2X02P-C28	2*2	2.00	4.00
HMT-PZ200V-2X03P-C28	2*3	4.00	6.00
HMT-PZ200V-2X04P-C28	2*4	6.00	8.00
HMT-PZ200V-2X05P-C28	2*5	8.00	10.00
HMT-PZ200V-2X06P-C28	2*6	10.00	12.00
HMT-PZ200V-2X07P-C28	2*7	12.00	14.00
HMT-PZ200V-2X08P-C28	2*8	14.00	16.00
HMT-PZ200V-2X09P-C28	2*9	16.00	18.00
.....			
HMT-PZ200V-2X40P-C28	2*40	(PIN-1) x 2.0	(PIN) x 2.0

GENERAL TOLERANCES UNLESS SPECIFIED		 深圳市华明通电子有限公司 HMTconn Shenzhen Huamingtong Electronics Co., Ltd		
X. ± 0.30	X.° ± 5°	PART NO.	TITLE:	
.X ± 0.25	.X° ± 1°	HMT-PZ200V-2XNP-C28	2.0PH H2.0 2xnPin 180度 PC2.8 PA3.9 PB2.0 L8.7 6T	
.XX ± 0.20	.XX° ± 0.5°	DESIGN: James	CUSTOMER	SIZE
MANUFACTURE DWG		CHED: Talen		UNITS
		APPD: Sophia		SCALE
				SHEET
			N:A	1/1