


# 客户图

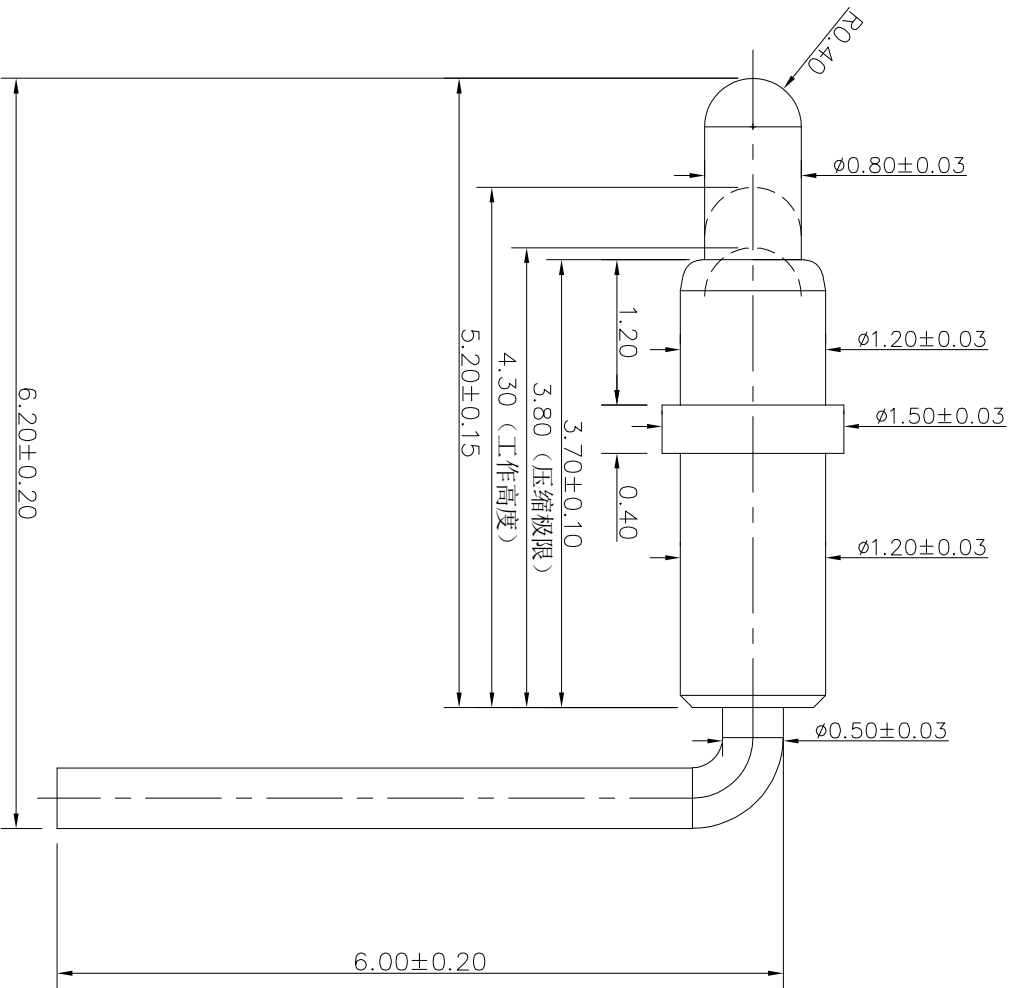

Note:

- 1: Material(材料) :  
Barrel: Brass C3602 (针管: 黄铜 C3602)  
Plunger: Brass C3604 (针头: 黄铜 C3604)  
Spring: SUS304 (弹簧: SUS304)
- 2: Plating(电镀) :  
Barrel: 3u' Au over 50~80u' Ni(针管: 镀金3u', 镍底50~80u')  
Plunger: 3u' Au over 50~80u' Ni (针头: 镀金3u', 镍底50~80u')  
Spring: No plated (弹簧: 不电镀)
- 3: Electrical(电气特性) :  
Rated Current & Voltage: DC 12V;1A (额定电压&电流: 直流12V,1A)  
Contact Resistance: 50 mohm Max. at working height.  
接触电阻: 最大50毫欧 (在工作高度状态下)
- 4: Mechanical(机械性能) :  
Force: 150g±20% at working height. (150g±20% 在工作高度)。  
Durability: 10,000 cycles(min) (寿命: 10000次)
- 5: WorkTemperature(工作环境):  
Withstanding Higt Temperature: 280t  
Operational Temperature: -40t~ +85t

NO.	ECN NO.	DESCRIPTION	DATE

深圳市鑫探技术有限公司

HTTP://WWW.XYZPOGOPIN.COM  
TEL:0755-28773277 FAX:0755-28891353



SCALE:	N/A	UNIT	mm
SHEET:	1 of 1	PROJECTION	1st Angle
DATE:	2026.04.11	VER.	A.0

THE UNMARKED TOLERANCE ARE AS BELOW :  
LENGTH: XXX ±0.05mm, XX ±0.10mm, X ±0.20mm  
ANGLE: XXX ±0.50°, XX ±1.00°, X ±2.00°

DESIGNED BY:	DWG. NO.	YZ134112062B-04
CHECKED BY:	TITLE:	Pogo pin 连接器
APPROVED BY:		