


# 客户图

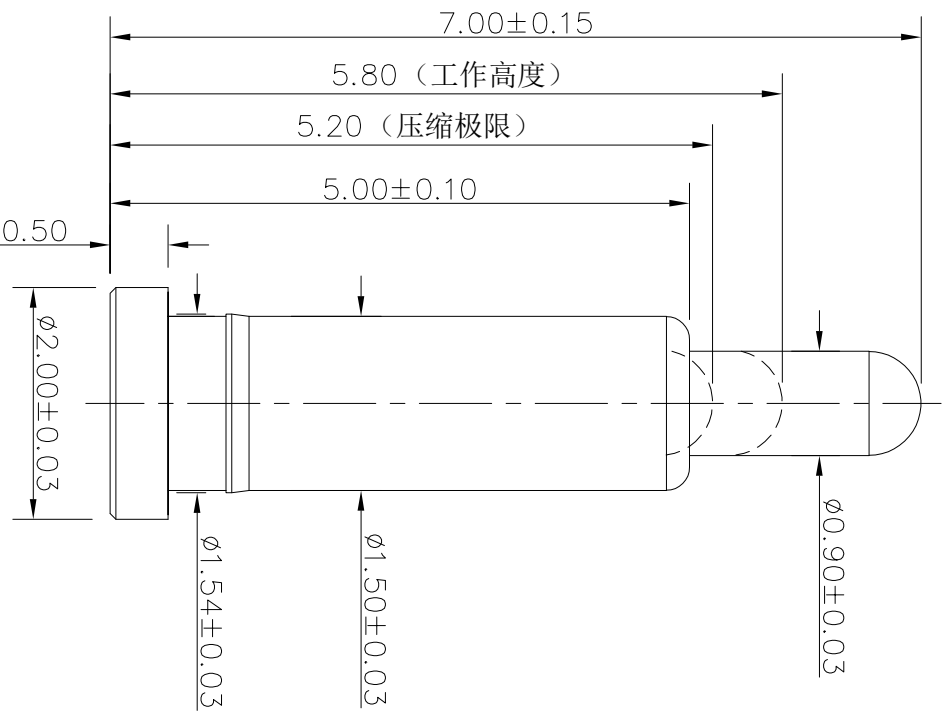

- Note:
- 1: Material(材料) :  
 Barrel: Brass C3604 (针管: 黄铜 C3604)  
 Plunger: Brass C3604 (针头: 黄铜 C3604)  
 Spring: SUS304 (弹簧: SUS304)
  - 2: Plating(电镀) :  
 Barrel: 3u' Au over 50~80u' Ni(针管: 镀金3u', 镍底50~80u'.)  
 Plunger: 3u' Au over 50~80u' Ni (针头: 镀金3u', 镍底50~80u'.)  
 Spring: Gold flash (弹簧: 镀金)
  - 3: Electrical(电气特性) :  
 Rated Current & Voltage: DC 12V;1A (额定电压&电流: 直流12V,1A)  
 Contact Resistance: 50 mohm Max. at working height.  
 接触电阻: 最大50毫欧 (在工作高度状态下)
  - 4: Mechanical(机械性能) :  
 Force: 20g±5g at working height. (20g±5g 在工作高度)。  
 Durability: 10,000 cycles(min) (寿命: 10000次)
  - 5: WorkTemperature(工作环境):  
 Withstanding Higt Temperature: 280t  
 Operational Temperature: -40t~ +85t

NO.	ECN NO.	DESCRIPTION	DATE

深圳市鑫探技术有限公司

HTTP://WWW.XYZPOGOPIN.COM  
 TEL:0755-28773277 FAX:0755-28891353



SCALE:	N/A	UNIT	mm
SHEET:	1 of 1	PROJECTION	第一角投影
DATE:	2026.04.11	VER.	A-1

THE UNMARKED TOLERANCE ARE AS BELOW :  
 LENGTH: XXX ±0.05mm, XXX ±0.10mm, X ±0.20mm  
 ANGLE: X.XX ±0.50°, X.XX ±1.00°, X. ±2.00°

DESIGNED BY:	DWG. NO.	YZ01415070R-03
CHECKED BY:	TITLE:	Pogo pin
APPROVED BY:		