


# 客户图

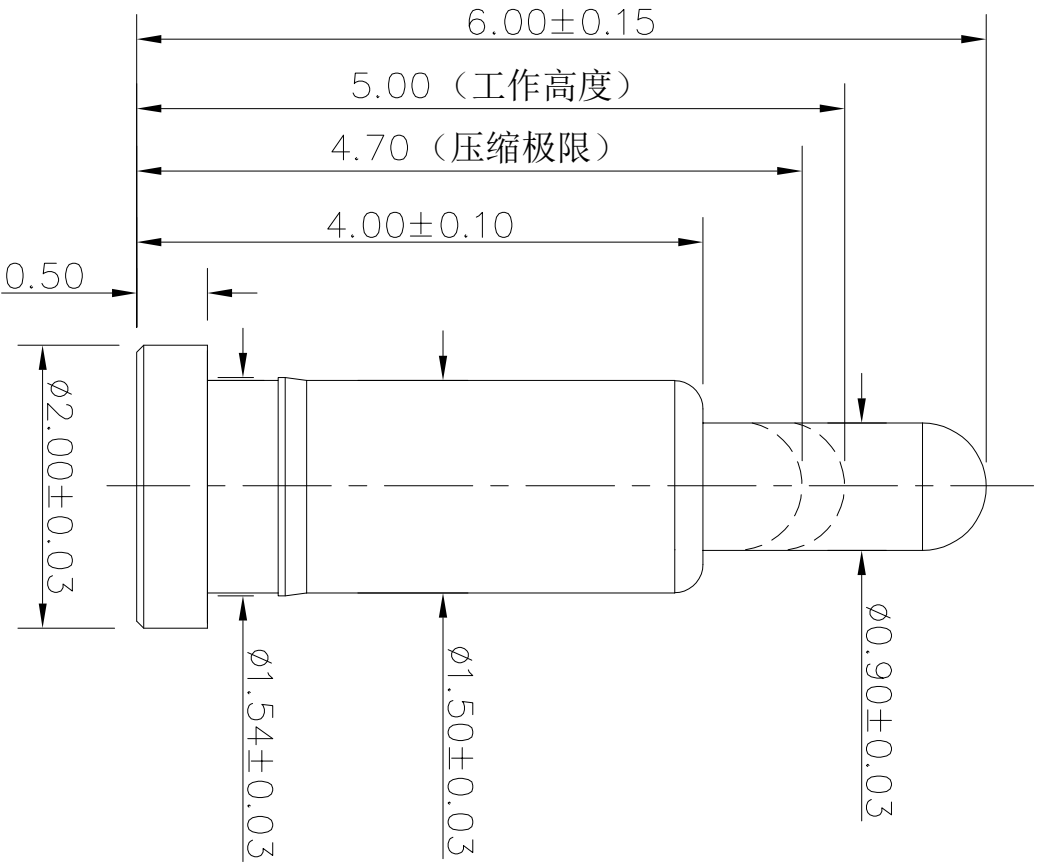

NO.	ECN NO.	DESCRIPTION	DATE
1			

Note:

- 1: Material(材料) :  
 Barrel: Brass C3604 (针管: 黄铜 C3604)  
 Plunger: Brass C3604 (针头: 黄铜 C3604)  
 Spring: SUS304 (弹簧: SUS304)
- 2: Plating(电镀) :  
 Barrel: 3u' Au over 50~80u' Ni(针管: 镀金3u', 镍底50~80u'.)  
 Plunger: 3u' Au over 50~80u' Ni(针头: 镀金3u', 镍底50~80u'.)  
 Spring: Gold flash (弹簧: 镀金)
- 3: Electrical(电气特性) :  
 Rated Current & Voltage: DC 12V;3A (额定电压&电流: 直流12V,3A)  
 Contact Resistance: 50 mohm Max. at working height.  
 接触电阻: 最大50毫欧 (在工作高度状态下)
- 4: Mechanical(机械性能) :  
 Force: 130g±20% at working height. (130g±20% 在工作高度)。  
 Durability: 10.000 cycles(min) (寿命: 10000次)
- 5: WorkTemperature(工作环境):  
 Withstanding Higt Temperature: 280℃  
 Operational Temperature: -20℃~ +70℃

深圳市鑫探技术有限公司

HTTP://WWW.XYZPOGOPIN.COM  
 TEL:0755-28773277 FAX:0755-28891353



SCALE:	N/A	UNIT	mm
SHEET:	1 of 1	PROJECTION	1st Angle
DATE:	2026.04.11	VER.	A.0

THE UNMARKED TOLERANCE ARE AS BELOW :	
LENGTH	ANGLE
XXX ±0.05mm XX ±0.10mm X ±0.20mm	X.XX ±0.50° X.X ±1.00° X ±2.00°

DESIGNED BY:	DWG. NO.	YZ01215060R-05
CHECKED BY:	TITLE:	Pogo pin
APPROVED BY:		