


NO.	ECN NO.	DESCRIPTION	DATE
1			

客户图

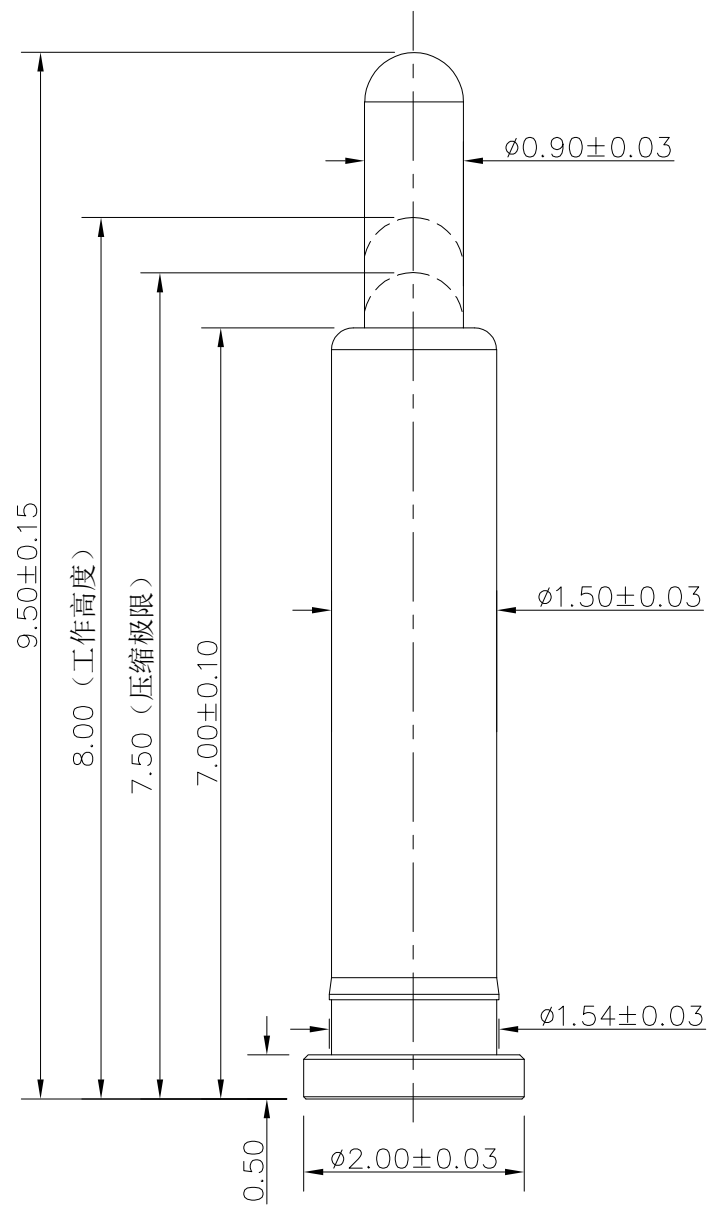

Note:

- Material(材料):
 - Barrel: Stainless steel SUS304 (针管: 不锈钢SUS304)
 - Plunger: Brass C3604 (针头: 黄铜 C3604)
 - Spring: SUS304 (弹簧: SUS304)
- Plating(电镀):
 - Barrel: Passivation (钝化)
 - Plunger: 3u' Au over 50~80u Ni (针头: 镀金3u', 镍底50~80u'。)
 - Spring: Gold flash (弹簧: 镀金)
- Electrical(电气特性):
 - Rated Current & Voltage: DC 12V;1A (额定电压&电流: 直流12V,1A)
 - Contact Resistance: 100 mohm Max. at working height. (接触电阻: 最大100毫欧 (在工作高度状态下))
- Mechanical(机械性能):
 - Force: 30g±20% at working height. (30g±20% 在工作高度)。
 - Durability: 10.000 cycles(min) (寿命: 10000次)
- WorkTemperture(工作环境):
 - Withstanding Higt Temperature: 280°C
 - Operational Temperature: -20°C~ +70°C

深圳市鑫探技术有限公司



HTTP://WWW.XYZPOGOPIN.COM
TEL:0755-28773277 FAX:0755-28891353

SCALE:	N/A	UNIT	mm
SHEET:	1 of 1	PROJECTION	
DATE:	2025.11.17	VER.	A.0

THE UNMARKED TOLERANCE ARE AS BELOW :			
LENGTH		ANGLE	
X.XX	±0.05mm	X.XX	±0.50°
X.X	±0.10mm	X.X	±1.00°
X.	±0.20mm	X.	±2.00°

DESIGNED BY:		DWG. NO.	YZ02015095R-03
CHECKED BY:		TITLE:	Pogo pin
APPROVED BY:			