


# 客户图

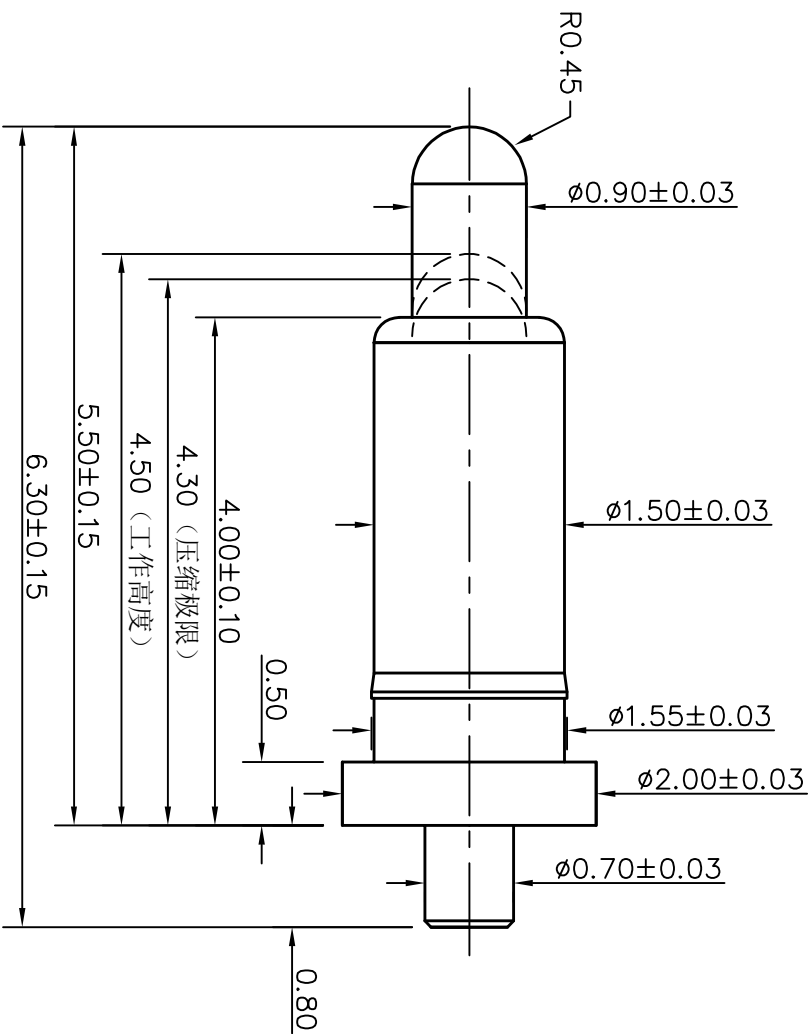

## Note:

- 1: Material(材料) :  
 Barrel: Brass C3604 (针管: 黄铜 C3604)  
 Plunger: Brass C3604 (针头: 黄铜 C3604)  
 Spring: SUS304 (弹簧: SUS304)
- 2: Plating(电镀) :  
 Barrel: 3u' Au over 50~80u' Ni(针管: 镀金3u', 镍底50~80u'.)  
 Plunger: 3u' Au over 50~80u' Ni (针头: 镀金3u', 镍底50~80u'.)  
 Spring: No plated (弹簧: 不电镀)
- 3: Electrical(电气特性) :  
 Rated Current & Voltage: DC 12V;2A (额定电压&电流: 直流12V,2A)  
 Contact Resistance: 50 mohm Max. at working height.  
 接触电阻: 最大50毫欧 (在工作高度状态下)
- 4: Mechanical(机械性能) :  
 Force: 25g±5g at working height. (25g±5g 在工作高度)。  
 Durability: 10,000 cycles(min) (寿命: 10000次)
- 5: Work Temperature(工作环境):  
 Withstanding Higt Temperature: 280t  
 Operational Temperature: - 40t~ + 85t

NO.	ECN NO.	DESCRIPTION	DATE

深圳市鑫探技术有限公司

HTTP://WWW.XYFPOGOPIN.COM  
 TEL:0755-28773277 FAX:0755-28891353



SCALE:	N/A	UNIT	mm
SHEET:	1 of 1	PROJECTION	A.0
DATE:	2026.04.11	VER.	

THE UNMARKED TOLERANCE ARE AS BELOW :			
LENGTH	ANGLE	DESIGNED BY:	DWG. NO.
XXX ±0.05mm	XXX ±0.50°		YZ127015063P-04
X.X ±0.10mm	X.X ±1.00°	CHECKED BY:	
X. ±0.20mm	X. ±2.00°	APPROVED BY:	TITLE: Pogo pin 连接器