


NO.	ECN NO.	DESCRIPTION	DATE
1			

客户图

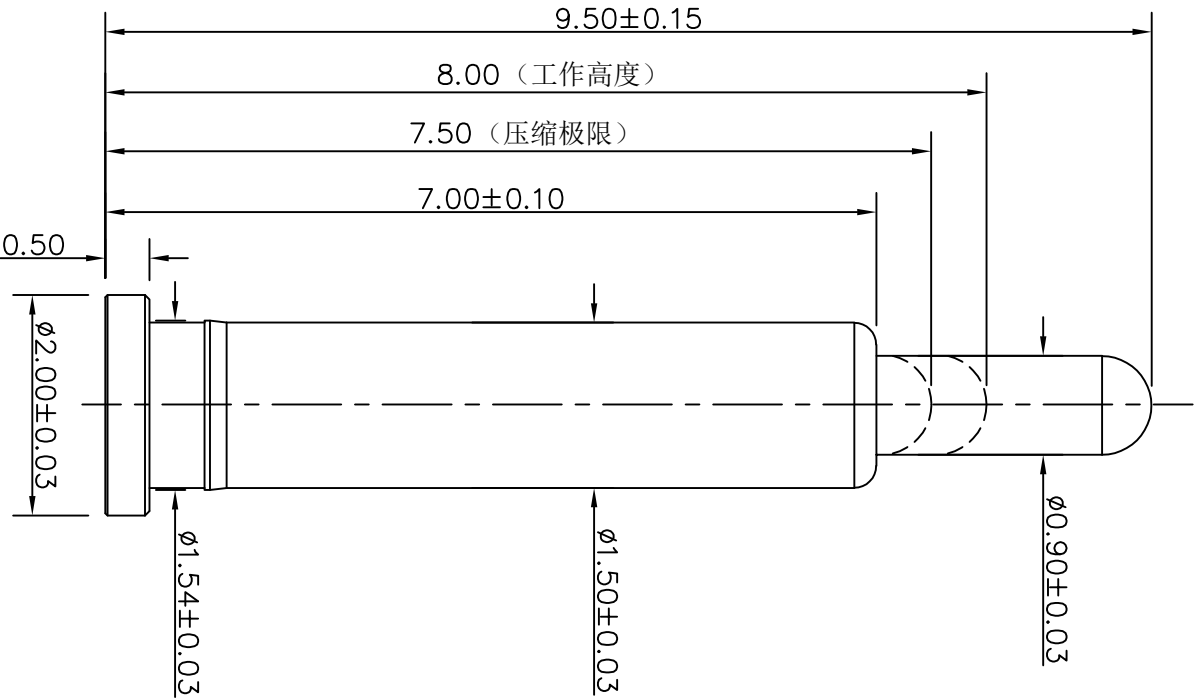

Note:

- 1: Material(材料) :
 Barrel: Brass C3604 (针管: 黄铜 C3604)
 Plunger: Brass C3604 (针头: 黄铜 C3604)
 Spring: SUS304 (弹簧: SUS304)
- 2: Plating(电镀) :
 Barrel: 3u' Au over 50~80u' Ni(针管: 镀金3u', 镍底50~80u'.)
 Plunger: 3u' Au over 50~80u' Ni (针头: 镀金3u', 镍底50~80u'.)
 Spring: No flash (弹簧: 不电镀)
- 3: Electrical(电气特性) :
 Rated Current & Voltage: DC 12V;1A (额定电压&电流: 直流12V,1A)
 Contact Resistance: 50 mohm Max. at working height.
 接触电阻: 最大50毫欧 (在工作高度状态下)
- 4: Mechanical(机械性能) :
 Force: 30g±20% at working height. (30g±20% 在工作高度)。
 Durability: 10,000 cycles(min) (寿命: 10000次)
- 5: WorkTemperature(工作环境):
 Withstanding Higt Temperature: 280t
 Operational Temperature: -20t~ +70t

深圳市鑫扬泽电子有限公司
 HTTP://WWW.XYZPOGOPIN.COM
 TEL:0755-28773277 FAX:0755-28891353



SCALE:	N/A	UNIT	mm
SHEET:	1 of 1	PROJECTION	1st Angle
DATE:	2023.4.7	VER.	A.0

THE UNMARKED TOLERANCE ARE AS BELOW :
 LENGTH: XXX ±0.05mm, XXX ±0.10mm, X ±0.20mm
 ANGLE: X.XX ±0.50°, X.X ±1.00°, X ±2.00°

DESIGNED BY:	DWG. NO.	YZ02015095R-04
CHECKED BY:	TITLE:	Pogo pin
APPROVED BY:		