

Core:TCS065125

Copper Wire:2UEW



Sloder:Sn99.3 Cu0.7



Electrical Specifications @25°C					
Part Number	Core	Inductance (1.0KHZ/0.25V)	Turns	DCR (S-F)	HI-POT (S-F)
		(uH)min	(S-F)	(mΩ Max)	(3S 2mA 60Hz)
TCS065125-150-P00156	TCS065125	15	1.0mm*2P*7.5TS	6.5	500Vac

MECHANICAL

SCHEMATICS

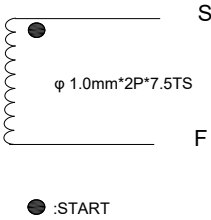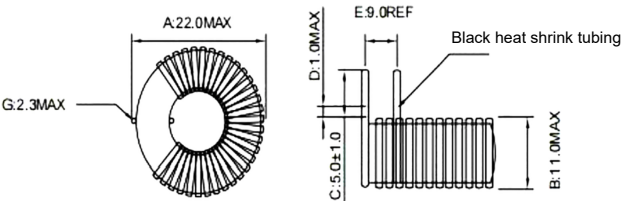

(UNIT: mm)