

Core:T6*3*3


Copper Wire:2UEW

Sloder:Sn99.3 Cu0.7



Electrical Specifications @25°C							
Part Number	Core	Inductance (1.0KHZ/0.25V)		Turns		DCR (N1-N2)	HI-POT (N1-N2)
		(uH)min	(uH)max	N1(1-2)	N2(3-4)	(mΩ Max)	(3S 2mA 60Hz)
T060303-151D-P01503	T6*3*3	150	10	0.30mm*7.5TS	0.30mm*7.5TS	35	500Vac

MECHANICAL

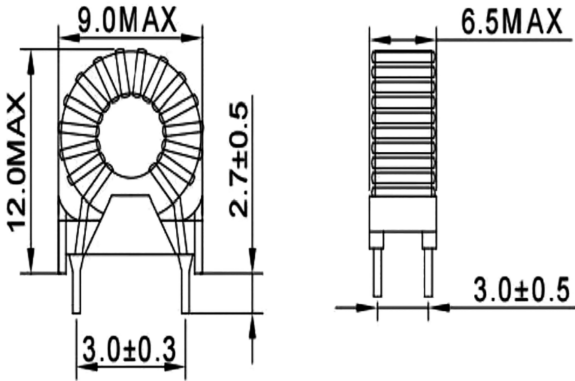

(UNIT: mm)

SCHEMATICS

