


客户图

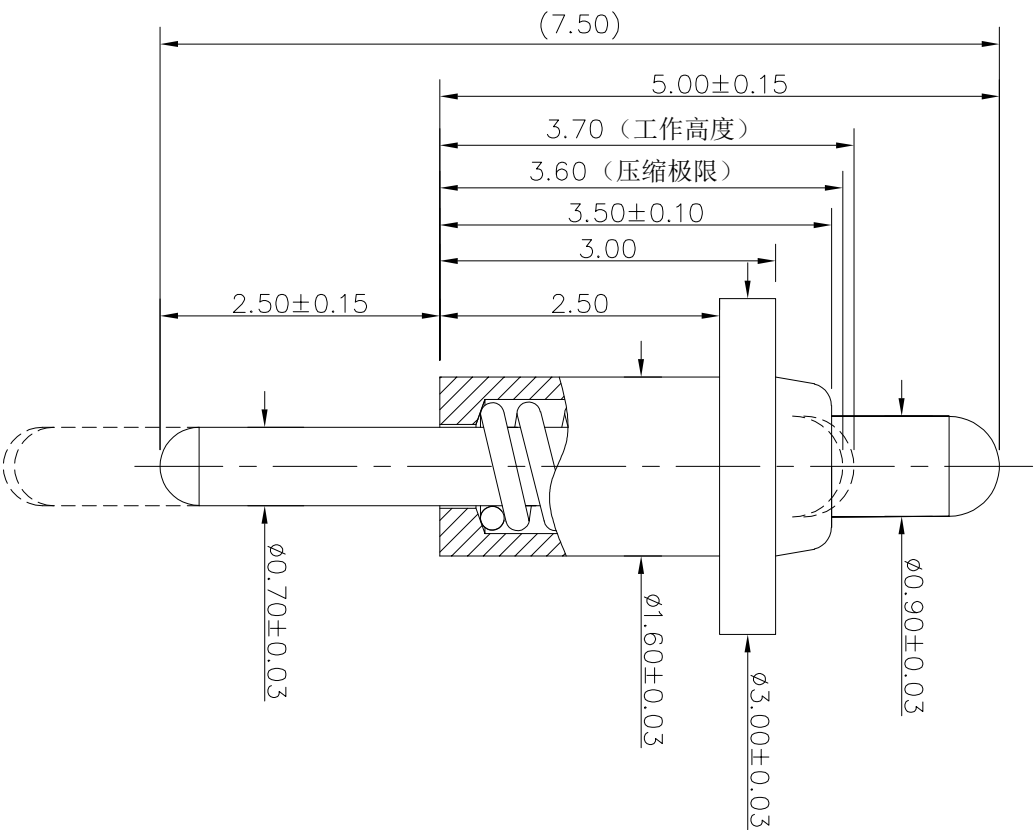

Note:

1: Material (材料) :

Barrel: Brass C3604 (针管: 黄铜 C3604)

Plunger: Brass C3604 (针头: 黄铜 C3604)

Spring: SUS304 (弹簧: SUS304)

2: Plating (电镀) :

Barrel: 1u' Au over 50~80u' Ni (针管: 镀金 1u', 镍底 50~80u'。)

Plunger: 3u' Au over 50~80u' Ni (针头: 镀金 3u', 镍底 50~80u'。)

Spring: No plated (弹簧: 不电镀)

3: Electrical (电气特性) :

Rated Current & Voltage: DC 12V; 10A (额定电压&电流: 直流 12V, 10A)

Contact Resistance: 50 mohm Max. at working height.

接触电阻: 最大 50 毫欧 (在工作高度状态下)

4: Mechanical (机械性能) :

Force: 70g ± 20% at working height. (70g ± 20% 在工作高度)。

Durability: 10.000 cycles (min) (寿命: 10000 次)

5: Work Temperature (工作环境) :

Withstanding Higt Temperature: 280°C

Operational Temperature: - 40°C ~ + 85°C

NO.	ECN NO.	DESCRIPTION	DATE

深圳市鑫探技术有限公司				HTTP://WWW.XYZPOGOPIN.COM				TEL:0755-28773277 FAX:0755-28891353							
				SCALE: N/A		UNIT		mm		THE UNMARKED TOLERANCE ARE AS BELOW :					
SHEET: 1 of 1		PROJECTION				A		LENGTH		ANGLE		DESIGNED BY:		DWG. NO.	
DATE: 2026.04.22		VER.						X.XX ±0.05mm		X.XX ±0.50°		CHECKED BY:		Pogo Pin	
								X.XX ±0.10mm		X.XX ±1.00°		APPROVED BY:			
								X. ±0.20mm		X. ±2.00°					