


客户图

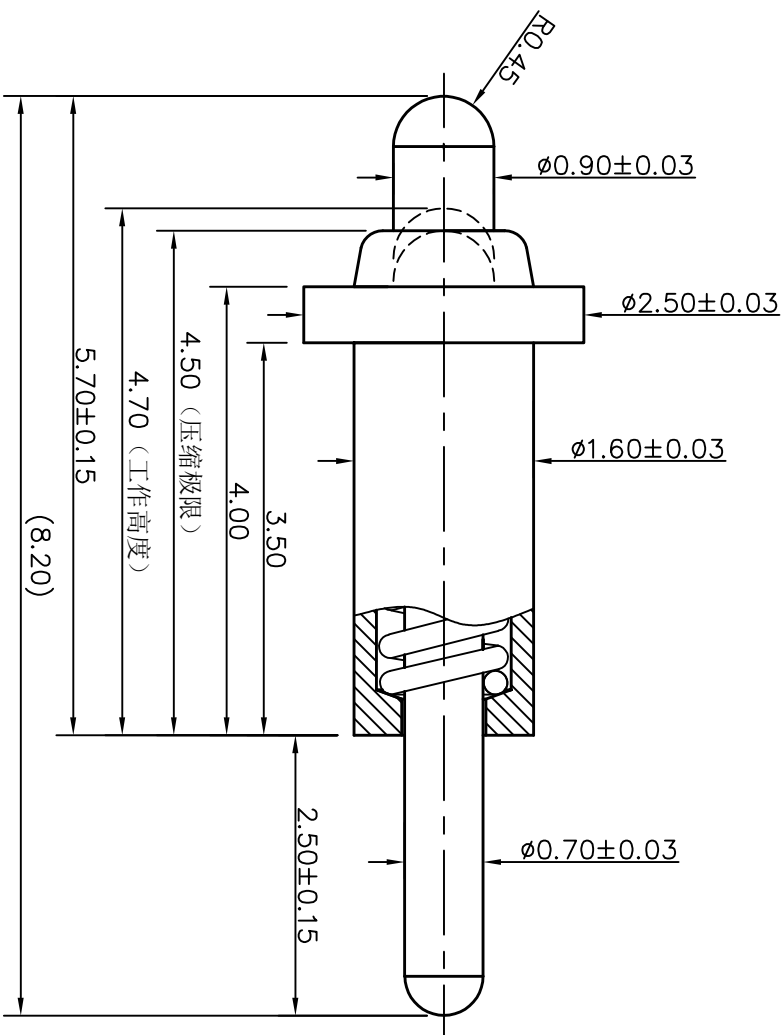

Note:

1: Material(材料):

Barrel: Brass C3604 (针管: 黄铜 C3604)
Plunger: Brass C3604 (针头: 黄铜 C3604)
Spring: SUS304 (弹簧: SUS304)

2: Plating(电镀):

Barrel: 1u' Au over 50~80u' Ni(针管: 镀金1u', 镍底50~80u'.)
Plunger: 3u' Au over 50~80u' Ni(针头: 镀金3u', 镍底50~80u'.)
Spring: No plated (弹簧: 不电镀)

3: Electrical(电气特性):

Rated Current & Voltage: DC 12V,5A (额定电压&电流: 直流12V,5A)
Contact Resistance: 50 mohm Max. at working height.
接触电阻: 最大50毫欧 (在工作高度状态下)

4: Mechanical(机械性能):

Force: 35g $\pm$ 20% at working height. (35g $\pm$ 20% 在工作高度)。
Durability: 10,000 cycles(min) (寿命: 10000次)

5: WorkTemperature(工作环境):

Withstanding Higt Temperature: 280 $^{\circ}$ C
Operational Temperature: -40 $^{\circ}$ C~ +85 $^{\circ}$ C

NO.	ECN NO.	DESCRIPTION	DATE

深圳市鑫探技术有限公司				SCALE:	N/A	UNIT	mm	THE UNMARKED TOLERANCE ARE AS BELOW:				DESIGNED BY:	DWG. NO.	YZ206116082P-01
HTTP://WWW.XYZPOGOPIN.COM				SHEET:	1 of 1	PROJECTION		LENGTH				CHECKED BY:		
TEL: 0755-28773277 FAX: 0755-28891353				DATE:	2026.04.22	VER.	D.0	ANGLE				APPROVED BY:		TITLE:
XY								X.XX $\pm$ 0.05mm X.XX $\pm$ 0.10mm X. $\pm$ 0.20mm						Pogo Pin