


客户图

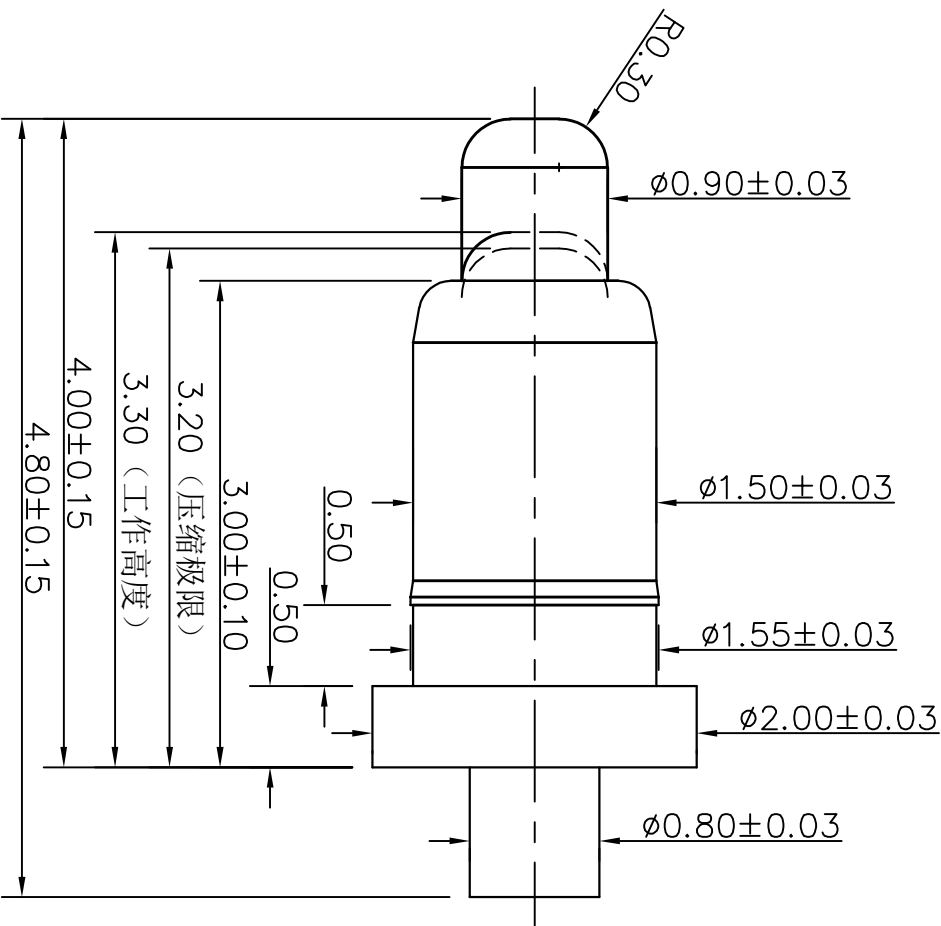

Note:

- 1: Material(材料):
Barrel: Brass C3604 (针管: 黄铜 C3604)
Plunger: Brass C3604 (针头: 黄铜 C3604)
Spring: SUS304 (弹簧: SUS304)
- 2: Plating(电镀):
Barrel: 3u' Au over 50~80u' Ni(针管: 镀金3u', 镍底50~80u'。)
Plunger: 3u' Au over 50~80u' Ni (针头: 镀金3u', 镍底50~80u'。)
Spring: Gold plated (弹簧: 镀金)
- 3: Electrical(电气特性):
Rated Current & Voltage: DC 12V,3A (额定电压&电流: 直流12V,3A)
Contact Resistance: 50 mohm Max. at working height.
接触电阻: 最大50毫欧 (在工作高度状态下)
- 4: Mechanical(机械性能):
Force: 100g±20% at working height. (100g±20%在工作高度)。
Durability: 10,000 cycles(min) (寿命: 10000次)
- 5: WorkTemperature(工作环境):
Withstanding Higt Temperature: 280℃
Operational Temperature: -40℃~ +85℃

NO.	ECN NO.	DESCRIPTION	DATE

深圳市鑫探技术有限公司									
HTTP://WWW.XYZPOGOPIN.COM									
TEL:0755-28773277 FAX:0755-28891353									
鑫探 XYZ									
SCALE:		N/A		UNIT		mm			
SHEET:		1 of 1		PROJECTION					
DATE:		2026.04.22		VER.		D.O			
THE UNMARKED TOLERANCE ARE AS BELOW :									
LENGTH					ANGLE				
X.XX ±0.05mm					X.XX ±0.50°				
X.X ±0.10mm					X.X ±1.00°				
X. ±0.20mm					X. ±2.00°				
DESIGNED BY:						DWG. NO.		YZ218115048P-02	
CHECKED BY:						TITLE:		Pogo pin连接器	
APPROVED BY:									

深圳市鑫探技术有限公司

HTTP://WWW.XYZPOGOPIN.COM
TEL:0755-28773277 FAX:0755-28891353

